


COIL: @ 25°C	
RESISTANCE	390 OHMS ± 10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	7.0 VDC
MUST RELEASE	0.63 VDC

CUSTOMER DATA SHEET

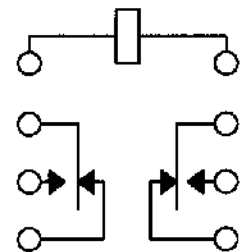

ENVIRONMENT:

VIBRATION	10	CPS TO	3000	CPS @	30	g's
SHOCK	75	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

NOTES:

OPERATE TIME	2.0 MS MAX
RELEASE TIME	1.5 MS MAX
CONTACT BOUNCE	1.5 MS MAX

DR. R.B. 9/26/97 *CR. Jerry* 9/26/97



CUST. C. I. I. STD
 CUST. NO. _____

TYPE "MA" RELAY

MAW-12S