


REV. 0
DCO 140959

COIL: @ 25°C	
RESISTANCE	390 OHMS ± 10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	7.1 VDC
MUST RELEASE	0.63 VDC

CUSTOMER DATA SHEET

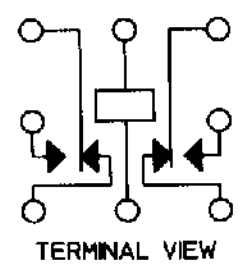

ENVIRONMENT:

VIBRATION	10	CPS TO	3000	CPS @	30	g's
SHOCK	75	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+200	°C		

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS
(BASED ON TEST DATA @ +125°C)

NOTES:

OPERATE TIME	2.0 MS MAX
RELEASE TIME	2.0 MS MAX
CONTACT BOUNCE	1.5 MS MAX

DR. R.B. 3/15/99 CK. 3/18/99



CUST. C.I.I. STD.
CUST. NO.

TYPE "MGAH" RELAY

MGAHC-12