


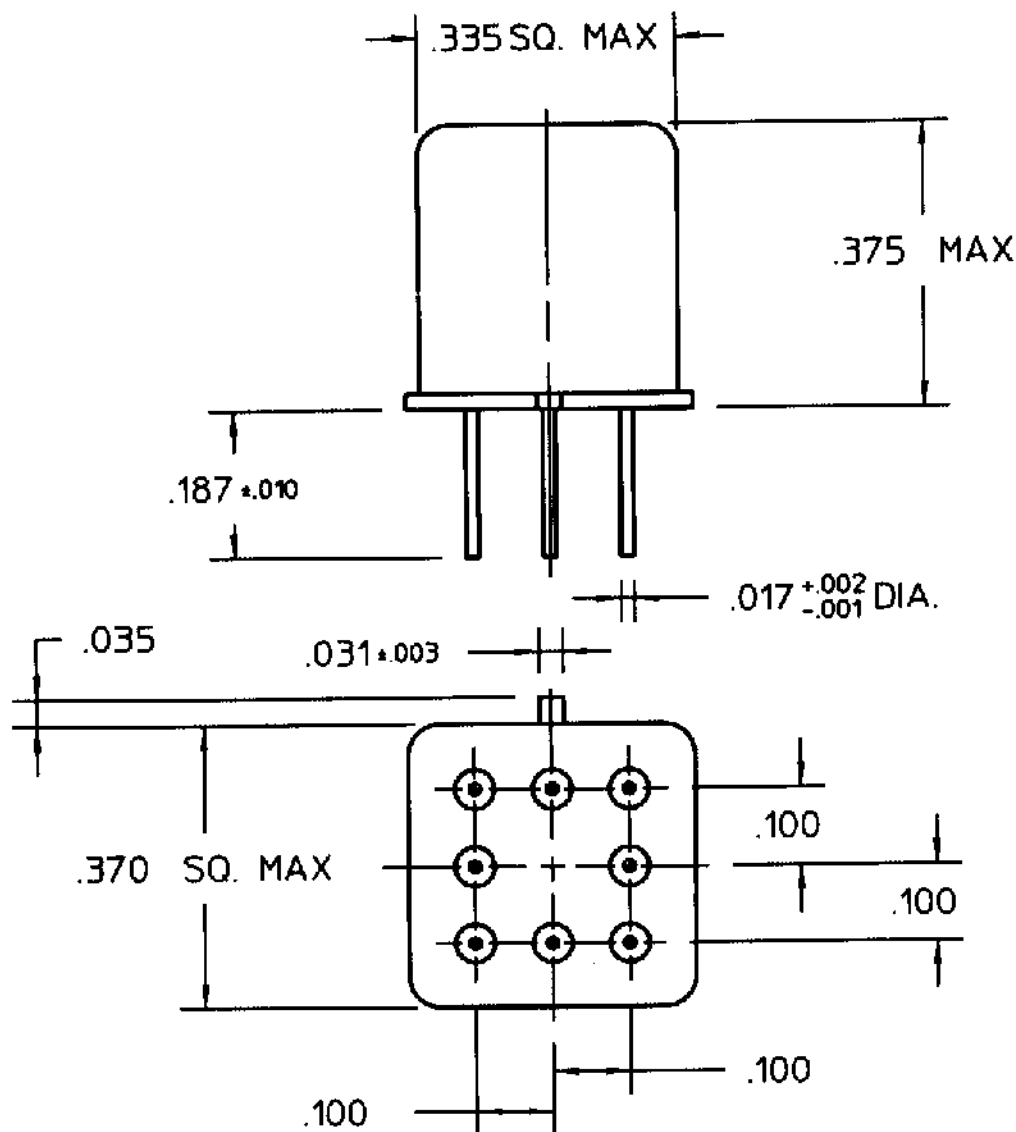

COIL: @ 25°C

RESISTANCE 1600 OHMS

NOMINAL VOLTAGE 18.0 VDC

MUST OPERATE 9.8 VDC

MUST RELEASE 0.92 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 75 g's 6 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX

RELEASE TIME 2.5 MS MAX

CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

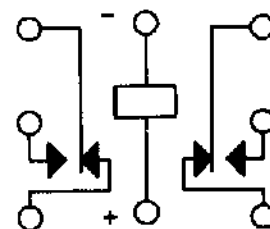

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. R.B. 6/12/95 CK. 6/12/95

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C.I.I. STD.

CUST. NO.

TYPE MGS RELAY

MGSP-18