


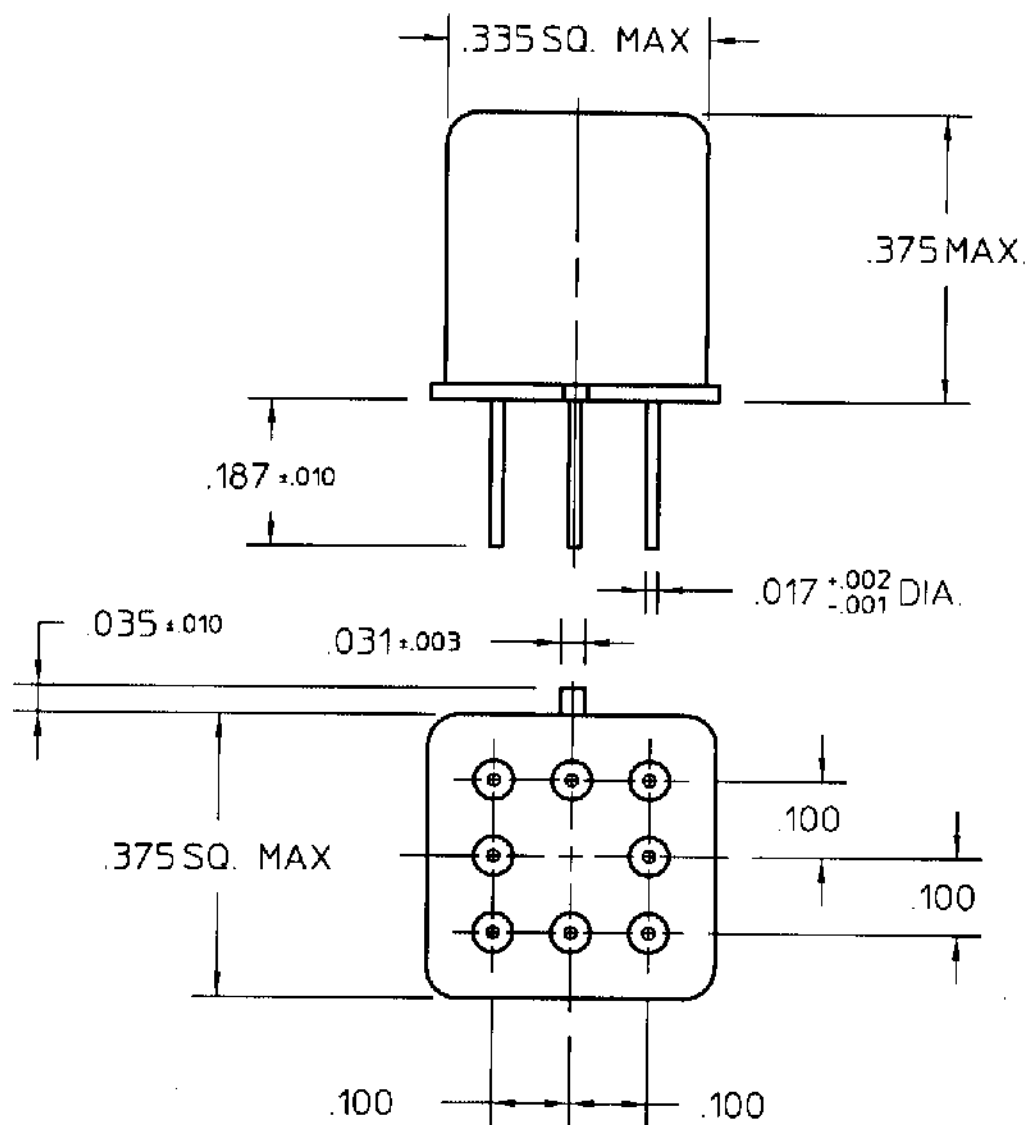

COIL: @ 25°C

RESISTANCE 100 OHMS ± 10%

NOMINAL VOLTAGE 5.0 VDC

MUST OPERATE 2.6 VDC

MUST RELEASE 0.23 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 75 g's 6 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX

RELEASE TIME 7.5 MS MAX

CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

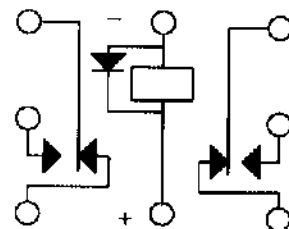

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. R.B. 11/11/97 *CK/12204* #11/97

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. C. I. I. STD.

CUST. NO.

TYPE MGSD RELAY

MGSPD-5