


REV. 1 9/25/98

COIL: @ 25°C	
RESISTANCE	100 OHMS ± 10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE VOLTAGE	2.8 VDC
TURN-ON BASE CURRENT	0.37 mADC
MUST RELEASE	0.22 VDC

CUSTOMER DATA SHEET

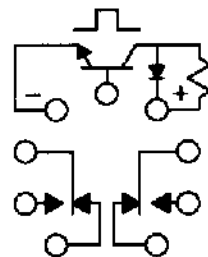

ENVIRONMENT:

VIBRATION	10	CPS TO	3000	CPS @	30	g's
SHOCK	75	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

NOTES:	TURN-ON TIME 4.0 MS MAX
	TURN-OFF TIME 7.5 MS MAX
	CONTACT BOUNCE 1.5 MS MAX

DR. R.B. 12/4/97 *OK* *ERRY* 9/28/98

 COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD.
CUST. NO. _____

TYPE 'MST' RELAY

MSCT-5