


COIL: @ 25°C	
RESISTANCE	850 OHMS ± 10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	7.0 VDC
MUST RELEASE	64 VDC

CUSTOMER DATA SHEET

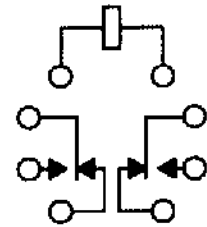

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

NOTES:	OPERATE TIME 4 MS MAX
	RELEASE TIME 2 MS MAX
	CONTACT BOUNCE 1.5 MS MAX

DR. R.B. 4/5/95 | *CK 4/5/95*

COMMUNICATIONS INSTRUMENTS, INC.

CUST. C. I. I.
 CUST. NO. STD.

TYPE 'MS' RELAY

MSW-12