


REV. 0
DCO 143516

COIL: @ 25°C	
RESISTANCE	850 OHMS ±10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	7.0 VDC
MUST RELEASE	0.64 VDC

ENVIRONMENT:	
VIBRATION	10 Hz TO 3000 Hz @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX.
RELEASE TIME 7.5 MS MAX.
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

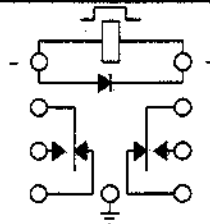

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
1 AMP 28 VDC RESISTIVE
100,000 OPERATIONS

DR. ASB 18 APR 02 *CK. Lero C 4/18/02*

CII Technologies
advanced control electronic solutions

CUST. C.I.I. STD
CUST. NO. REV.

"MSD" RELAY

MSWDG-12S