


REV. 0  
DCO 143523

|                 |              |
|-----------------|--------------|
| COIL: @ 25°C    |              |
| RESISTANCE      | 45 OHMS ±20% |
| NOMINAL VOLTAGE | 3.3 VDC      |
| MUST OPERATE    | 1.9 VDC      |

CUSTOMER DATA SHEET

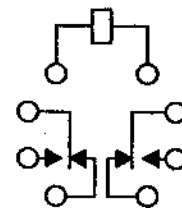

TERMINAL VIEW

MUST RELEASE \_\_\_\_\_

|              |     |              |     |
|--------------|-----|--------------|-----|
| ENVIRONMENT: |     |              |     |
| VIBRATION    | 10  | CPS TO       | 500 |
|              |     | CPS @        | 10  |
|              |     | g's          |     |
| SHOCK        | 30  | g's          | 6   |
|              |     | MS. DURATION |     |
| TEMPERATURE  | -55 | °C TO        | +85 |
|              |     | °C           |     |

CONTACT RATING: LOW LEVEL TO 1A  
28 VDC RESISTIVE 100,000 OPERATIONS

NOTES: OPERATE TIME 6.0 MS MAX.  
RELEASE TIME 3.0 MS MAX.

DR. B.D. 30APR02

CK 5/1/02 AB



CUST. C.I.I.  
CUST. NO. STD. REV.

"MW3" RELAY  
3GHZ

MW 3S-3P