


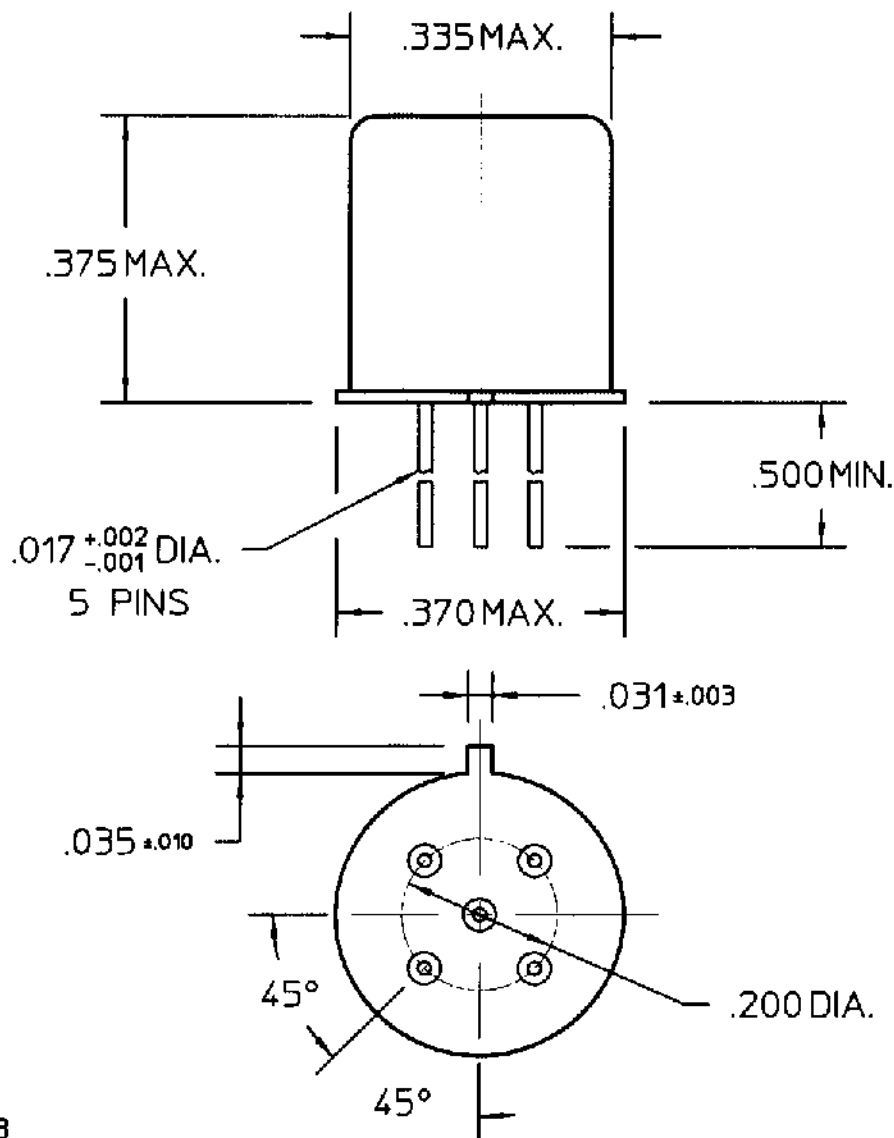

REV. 0

DCO 141243

COIL: @ 25°C
 RESISTANCE 4000 OHMS $\pm$ 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 14.2 VDC
 MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX

RELEASE TIME 2.5 MS MAX

CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

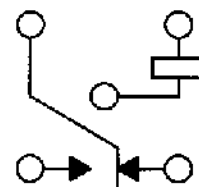

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 8/12/99 CK. 8/12/99



COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C. I. I.

CUST. NO. STANDARD

REV.

"PR1MS" RELAY

PR1MSC-26X