

REV. 0
DCO 141243


COIL: @ 25°C	
RESISTANCE	125 OHMS ±10%
NOMINAL VOLTAGE	5.0 VDC
MUST OPERATE	2.8 VDC
MUST RELEASE	1.4 VDC MAX, 0.23 VDC MIN.

ENVIRONMENT:

VIBRATION	10	CPS TO	3000	CPS @	30	g's
SHOCK	75	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 2.5 MS MAX
CONTACT BOUNCE 15 MS MAX

CUSTOMER DATA SHEET

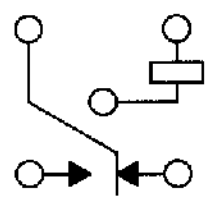

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 8/12/99 CKJ/ERY 8/12/99



CUST. C. I. I.
CUST. NO. STANDARD REV.

PR1MS RELAY

PR1MSC-5X