

REV. 0

DCO 141404


COIL: @ 25°C	
RESISTANCE	98 OHMS ±10%
NOMINAL VOLTAGE	6.0 VDC
MUST OPERATE	3.5 VDC
MUST RELEASE	2.0 VDC MAX, 0.28 VDC MIN

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
 SHOCK 75 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX.  
RELEASE TIME 15 MS MAX.  
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

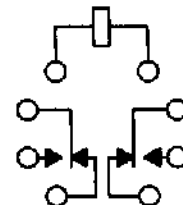

TERMINAL VIEW

CONTACT RATING: 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 9/28/99

*CK* *9/20/99*

**COMMUNICATIONS INSTRUMENTS, INC.**

CUST. C.I.I.  
 CUST. NO. COTS STANDARD REV. \_\_\_\_\_

PRMA RELAY

PRMAC-6X