


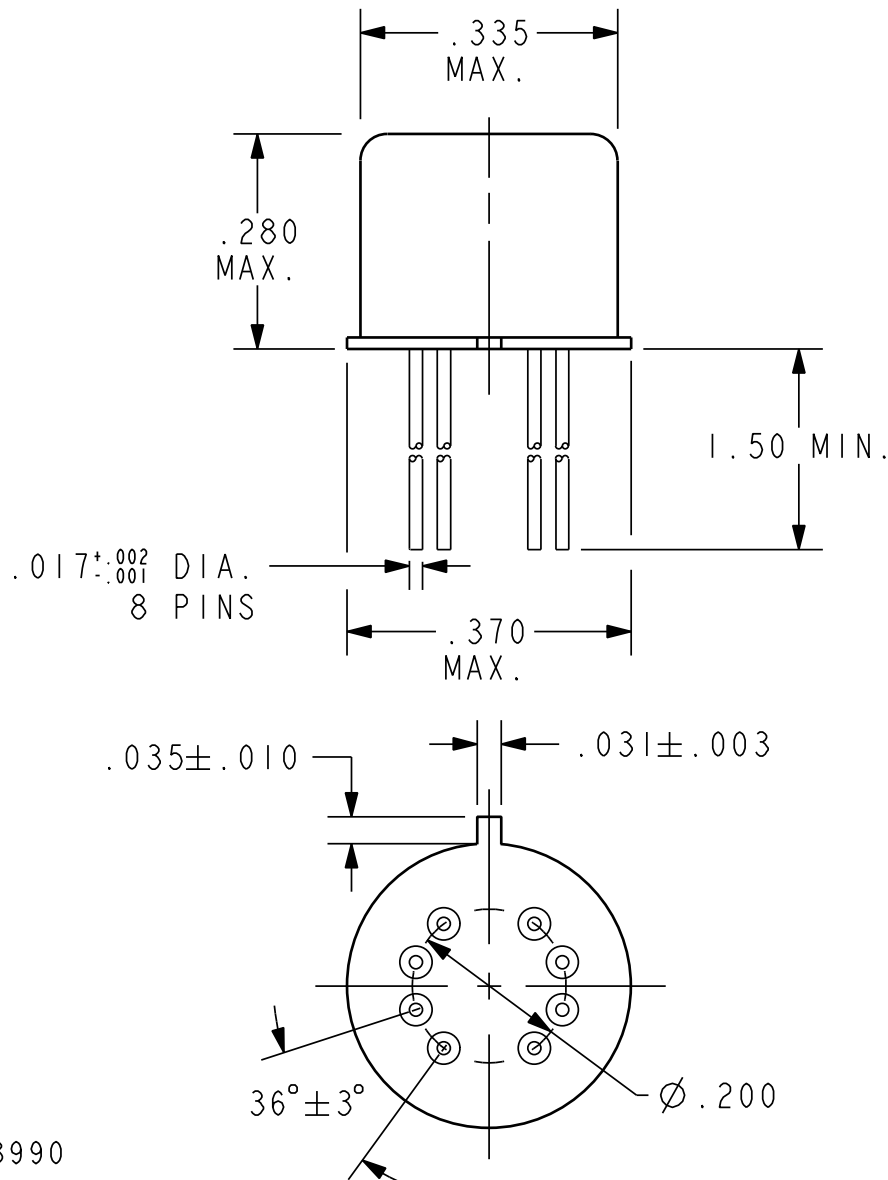


REV. 0
DCO 143990

COIL: @ 25°C
RESISTANCE 390 OHMS ±10%
NOMINAL VOLTAGE 12.0 VDC
MUST OPERATE 7.0 VDC
MUST RELEASE 4.0 VDC MAX., 0.63 VDC MIN.

ENVIRONMENT:
VIBRATION 10 Hz TO 3000 Hz @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C
NOTES: OPERATE TIME 2.0 MS MAX.
RELEASE TIME 1.5 MS MAX.
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

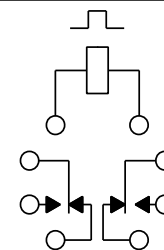

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 06JAN2005 CK, JERRY C. 1/6/05

CII Technologies
advanced control electronic solutions

CUST. CII
CUST. NO. COTS STANDARD REV.

"PRMA" RELAY

PRMAW-12X