


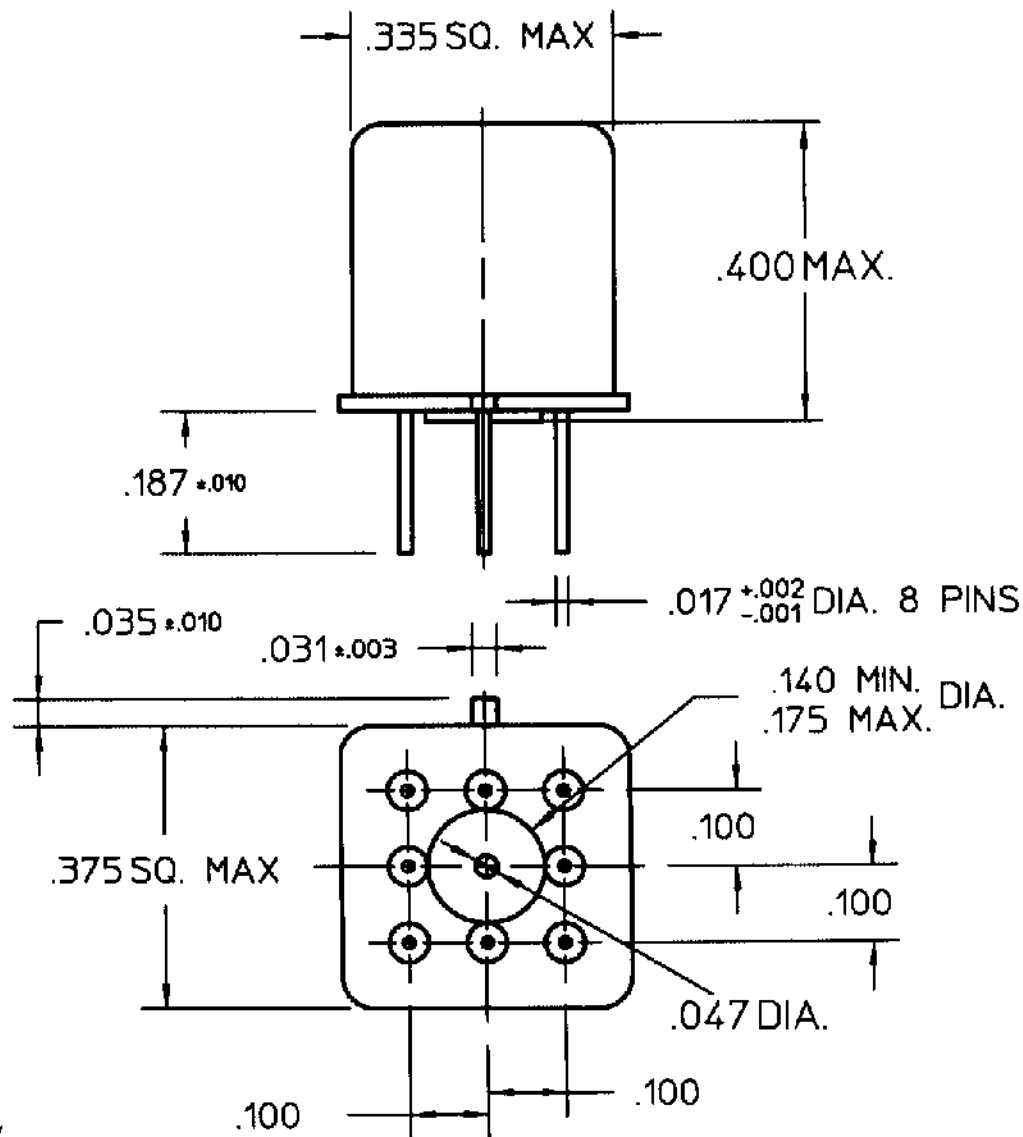

REV. 0
DCO 140824


COIL: @ 25°C
 RESISTANCE 64 OHMS ± 10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 2.9 VDC
 MUST RELEASE 0.8 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 7.5 MS MAX
CONTACT STABILIZATION 2.5 MS MAX.

CUSTOMER DATA SHEET

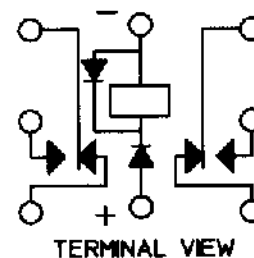

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. R.B. 12/18/98 CK. ERRA 12/18/98

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I.
 CUST. NO. COTS STD.

TYPE "PRMGSPDD" RELAY

PRMGSPDD-5YW