


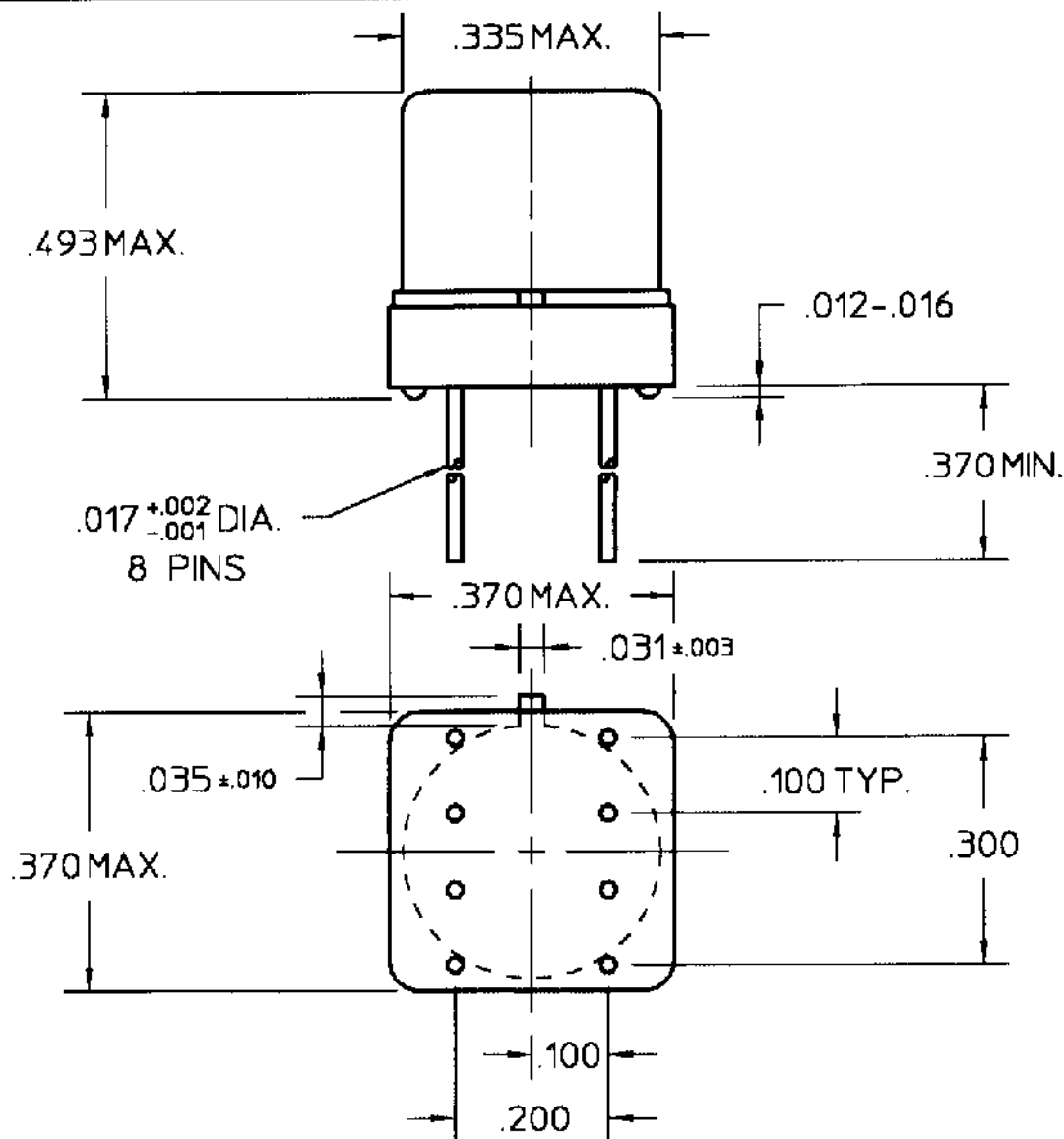

COIL: @ 25°C
 RESISTANCE 100 OHMS $\pm$ 10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 2.6 VDC
 MUST RELEASE 1.4 VDC MAX, 0.23 VDC MIN.

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 75 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX
 RELEASE TIME 2.0 MS MAX
 CONTACT STABILIZATION TIME 2.0 MS MAX

CUSTOMER DATA SHEET

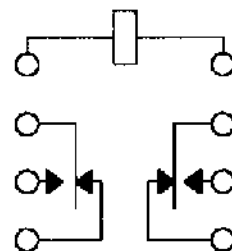

CONTACT RATING: LOW LEVEL TO
 1A 28 VDC RESISTIVE 100,000
 OPERATIONS

DR. R.B. 6/16/98 CK. *6/16/98*

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C. I. I.
 CUST. NO. COTS

TYPE PRMS RELAY

PRMSC-5ZS