


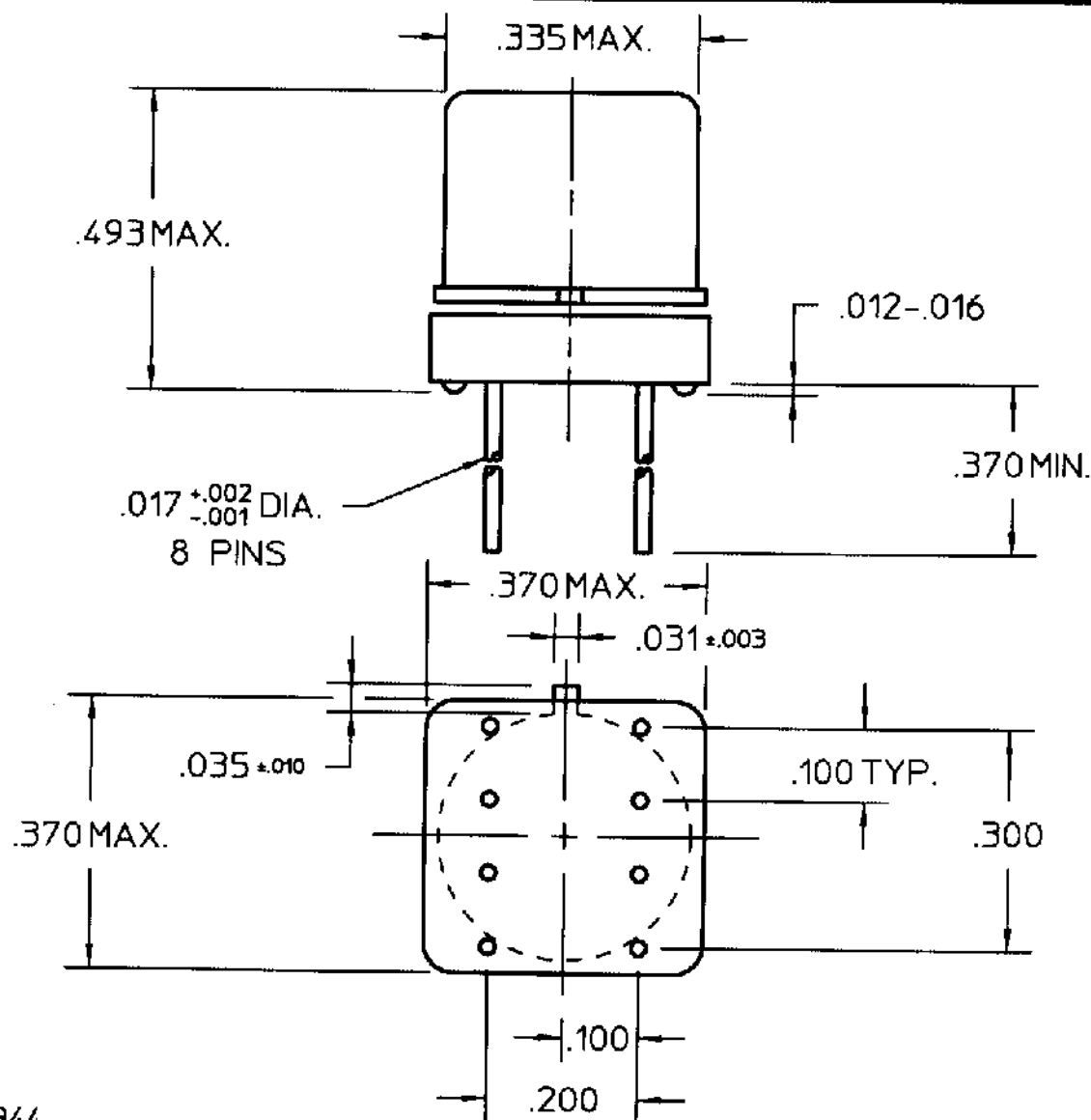


REV. 0
DCO 140944

COIL: @ 25°C
RESISTANCE 100 OHMS $\pm$ 10%
NOMINAL VOLTAGE 5.0 VDC
MUST OPERATE 2.6 VDC
MUST RELEASE 1.4 VDC MAX, 0.23 VDC MIN.

ENVIRONMENT:
VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 7.5 MS MAX
CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

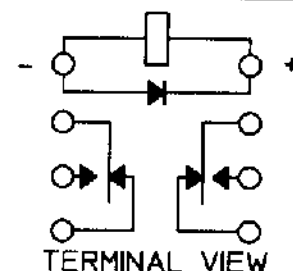

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

DR. R.B. 3/4/99 EK 3-4-99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I.
CUST. NO. COTS

TYPE "PRMSD" RELAY

PRMSCD-5XS