


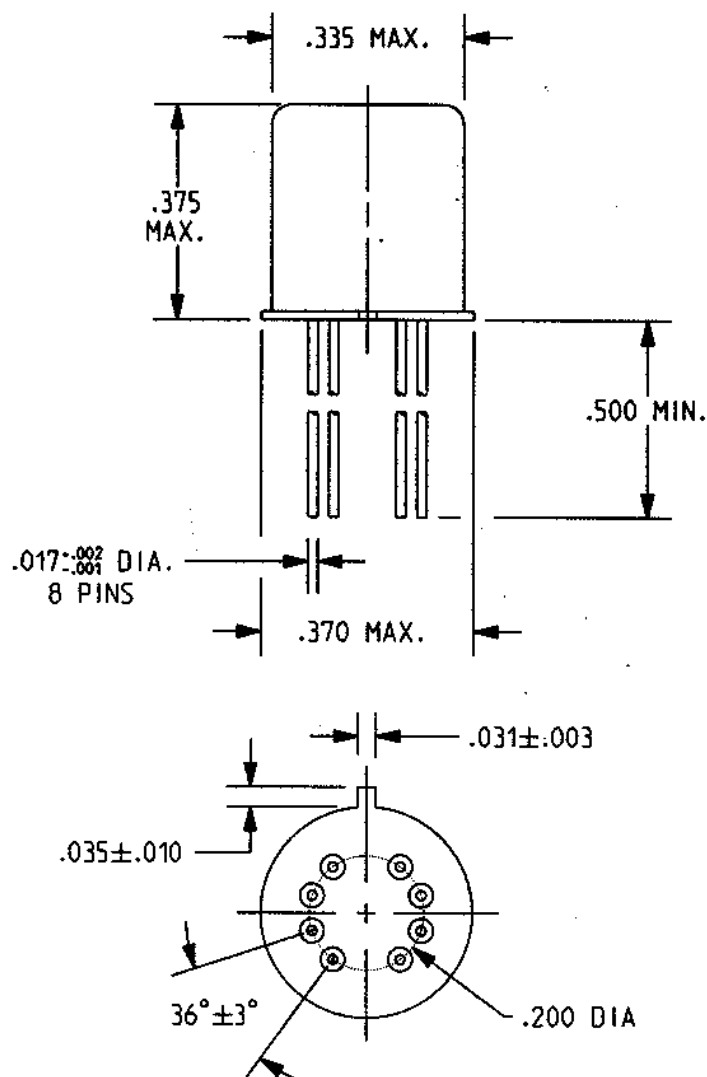

REV. 0

DCO 143715

COIL: @ 25 $^\circ$ C
 RESISTANCE 850 OHMS $\pm$ 10%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 7.8 VDC
 MUST RELEASE 4.6 VDC MAX, 1.3 VDC MIN.

ENVIRONMENT:

VIBRATION 10 Hz TO 3000 Hz @ 30 g's

SHOCK 75 g's 6 MS. DURATION


TEMPERATURE -65 $^\circ$ C TO +125 $^\circ$ C

NOTES: OPERATE TIME 4.0 MS MAX.

RELEASE TIME 7.5 MS MAX.

CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

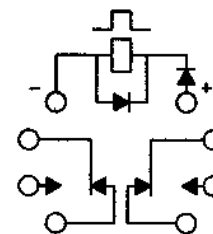

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 09JAN03

CK *[Signature]* 01/09/03

CII Technologies
 advanced control electronic solutions

CUST. NO. COTS STD REV.

"PRMSDD" RELAY

PRMSCDD-12X