


REV. 0
DCO 143204

COIL: @ 25°C	
RESISTANCE	850 OHMS ±10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	7.0 VDC
MUST RELEASE	4.0 VDC MAX, 0.64 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE TIME 4.0 MS MAX
	RELEASE TIME 7.5 MS MAX
	CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

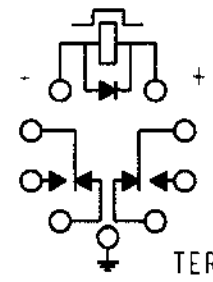

TERMINAL VIEW

CONTACT RATING:	LOW LEVEL TO 1A
	28 VDC RESISTIVE 100,000 OPERATIONS

DR. BSH 9/12/01 CK. JERRY 9/12/01



CUST. CII	PRMSD RELAY
CUST. NO. COTS STD. REV.	

PRMSCDG-12X