
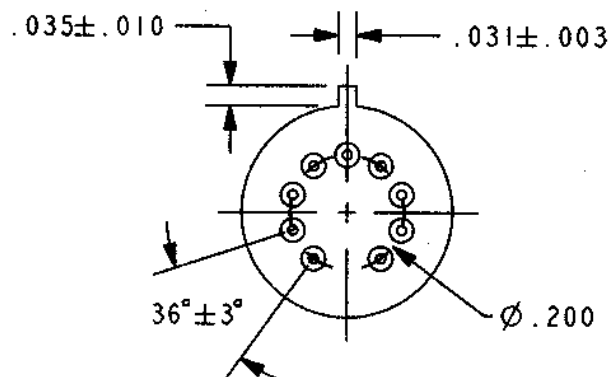


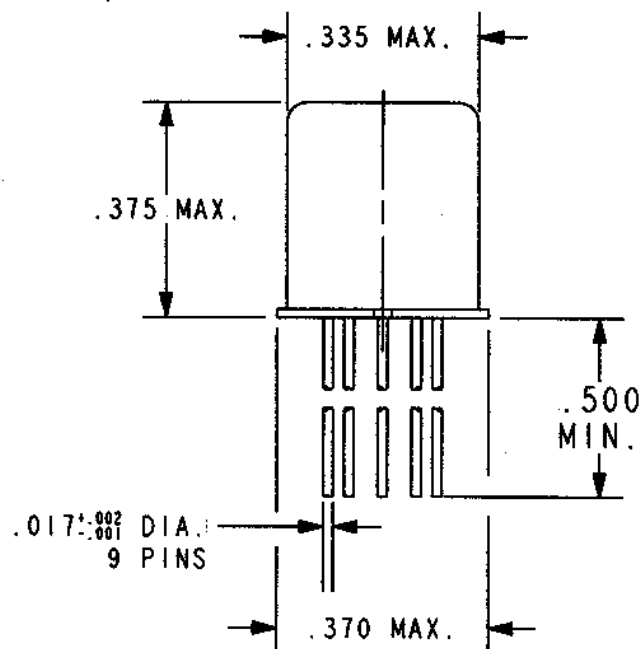


REV. 0
DCO 143715

COIL: @ 25°C
RESISTANCE 3300 OHMS ±10%
NOMINAL VOLTAGE 26.5 VDC
MUST OPERATE 14.2 VDC
TURN -ON BASE CURRENT 0.06 mADC
MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:
VIBRATION 10 Hz TO 3000 Hz @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES:
TURN-ON TIME 4.0 MS MAX
TURN-OFF TIME 7.5 MS MAX
CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

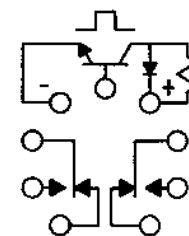

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 09JAN03 CK. 01/09/03

CII Technologies
advanced control electronic solutions

CUST. NO. COTS100 REV.

"PRMST" RELAY

PRMSCT-26X