


REV. 0  
DCO 143888

COIL: @ 25°C  
 RESISTANCE 850 OHMS ±10%  
 NOMINAL VOLTAGE 12.0 VDC  
 MUST OPERATE 7.0 VDC  
 MUST RELEASE 4.0 VDC MAX., 0.64 VDC MIN.

ENVIRONMENT:  
 VIBRATION 10 Hz TO 3000 Hz @ 30 g's  
 SHOCK 75 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C  
 NOTES: OPERATE TIME 4.0 MS MAX.  
RELEASE TIME 2.0 MS MAX.  
CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

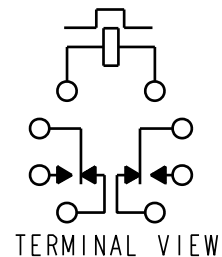

CONTACT RATING: LOW LEVEL TO  
1A 28 VDC RESISTIVE 100,000  
OPERATIONS

DR. ASB 14MAY04 CK. JERRY C 5/17/04

**CII Technologies™**  
 advanced control electronic solutions

CUST. C.I.I.  
 CUST. NO. COTS STANDARD REV. \_\_\_\_\_

"PRMS" RELAY

PRMSP-12X