



Harnessing > Adhesives & Sealants > Fusion Tape



Tape Type: **Master Electrician's**

Fusion Tape Tape Width: 19.05 mm [.75 in]

Fusion Tape Roll Length: 20.11674 m [65.9998 ft]

Fusion Tape Color: **Black**

Fusion Tape Thickness: .18 mm [.007 in]

Features

Product Type Features

Product Type	Accessory
Tape Type	Master Electrician's
Center Stripe	No

Body Features

Fusion Tape Color	Black
-------------------	-------

Dimensions

Fusion Tape Tape Width	19.05 mm [.75 in]
Fusion Tape Thickness	.18 mm [.007 in]

Packaging Features

Packaging Quantity	10
Packaging Method	Roll
Fusion Tape Roll Length	20.11674 m [65.9998 ft]

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUN 2020 (209)



Candidate List Declared Against: JUN 2020
(209)

Does not contain REACH SVHC

Halogen Content

Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free

Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 605980-3
FUSION TAPE, 1.5" X .020" X 30FT



TE Part # 1-608036-4
SILICONE FUSION TAPE, 1" X 15'



TE Part # 608036-4
SILICONE FUSION TAPE, 1" X 36'



TE Part # 608036-1
SILICONE FUSION TAPE, 1" X 36'



TE Part # 605980-2
FUSION TAPE, 1" X .020" X 30FT



TE Part # 605262-2
FUSION TAPE, 2" X .020" X 30FT



TE Part # 1-608036-3
SILICONE FUSION TAPE, 1" X 15'



TE Part # 608036-2
SILICONE FUSION TAPE, 1" X 36'



TE Part # 1-608036-2
SILICONE FUSION TAPE, 1"X36'



TE Part # 608036-9
SILICONE FUSION TAPE,1.5"X36'



TE Part # 605980-1
FUSION TAPE, .75"X .020"X 30FT



TE Part # 605262-1
FUSION TAPE, 1" X .020" X 10FT

Customers Also Bought



TE Part #6-2213772-5
AV22 DPL 5A MOVE RING LED RED
12V




TE Part #221629-2
TERMINATOR,BNC,75 OHM,1 WATT




TE Part #1423674-5
W54-XB1A4A10-8=CKTBKR,THERM,PB



TE Part #4-1879355-8
RR03 5% 390K AMMO

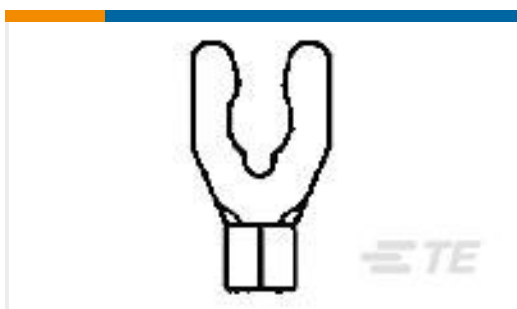

TE Part #53013-1
TERMINAL,BUDG SPR SPD 12-10 5

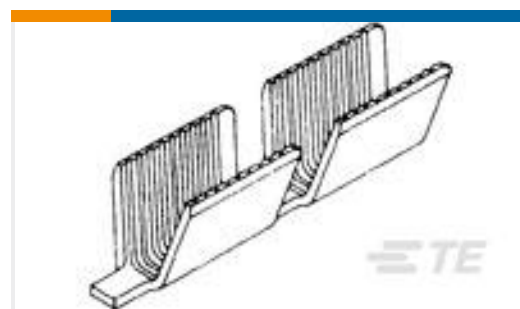

TE Part #1742898-1
AMVAR SPLC 10M-22M 0295 TPBR



TE Part #1-1879354-2
RR03 5% R91 AMMO



TE Part #5225555-8
TNC PLUG



TE Part #5225554-9
TNC RT ANG PLUG DUAL



TE Part #2-1437572-6
TPC13F0=SW P/B MOMENTARY

Documents

Product Drawings

ELECTRICAL TAPE, PVC, BLACK

English