


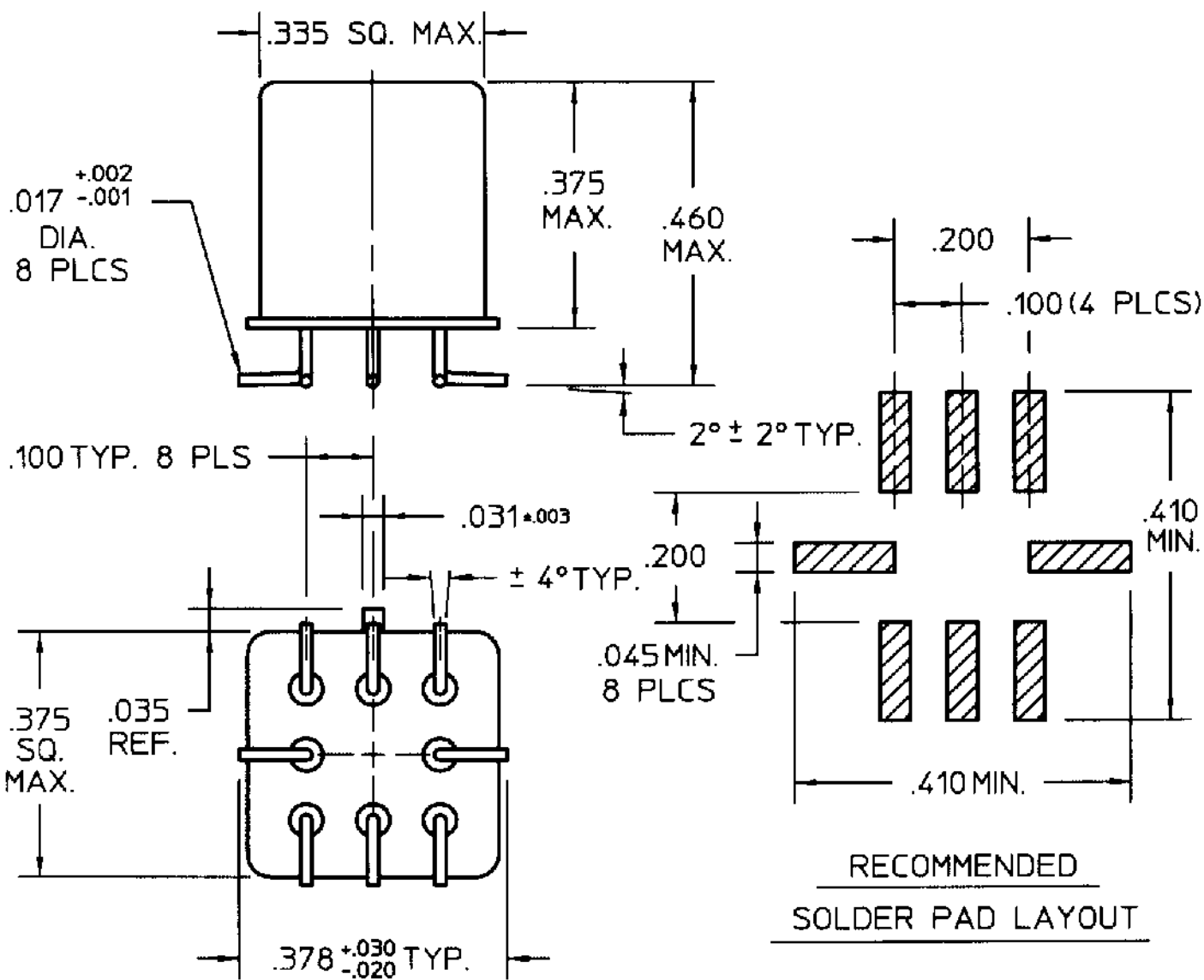


COIL: @ 25°C  
 RESISTANCE 3200 OHMS  $\pm$  10%  
 NOMINAL VOLTAGE 26.5 VDC  
 MUST OPERATE 14.0 VDC  
 MUST RELEASE 1.4 VDC

ENVIRONMENT:  
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
 SHOCK 75 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 4.0 MS MAX.  
 RELEASE 2.0 MS MAX.  
 CONTACT BOUNCE 1.5 MS MAX.

## CUSTOMER DATA SHEET

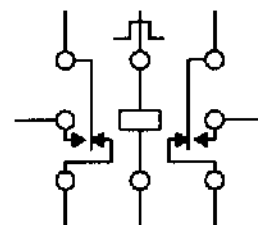

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP  
 28 VDC RESISTIVE 100,000 OPERATIONS MIN.

DR. R.B. 11/20/98 CK V/3/78/11

COMMUNICATIONS  
 INSTRUMENTS, INC.

CUST. C. I. I. STD.  
 CUST. NO.

TYPE SMGS RELAY

SMGS-26