


REV. A
DCO 143860

COIL: @ 25°C	
RESISTANCE	100 OHMS ±10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	6.5 VDC
MUST RELEASE	4.2 VDC MAX, 0.92 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 Hz TO 2000 Hz @ 15 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES: OPERATE & RELEASE 7 MS MAX.
(INCLUDING BOUNCE)

CUSTOMER DATA SHEET

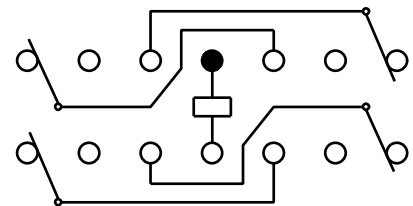

TERMINAL VIEW

CONTACT RATING:	LOW LEVEL TO
	2 AMP 28 VDC RESISTIVE
	100,000 OPERATIONS

DR. B.D. 11MAR04 CK. J.M.B. 3/11/04

CII Technologies
advanced control electronic solutions

CUST. QPL
CUST. NO. M39016/40-010 REV.

"SR" RELAY

SR-7622