
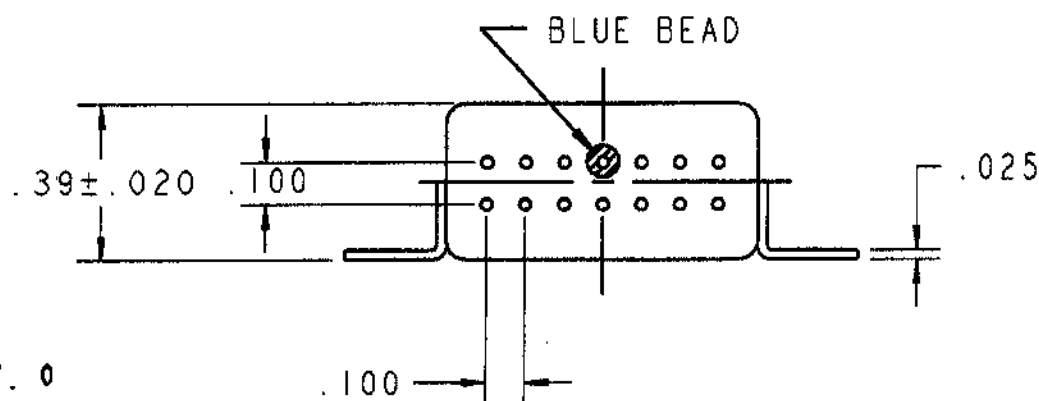


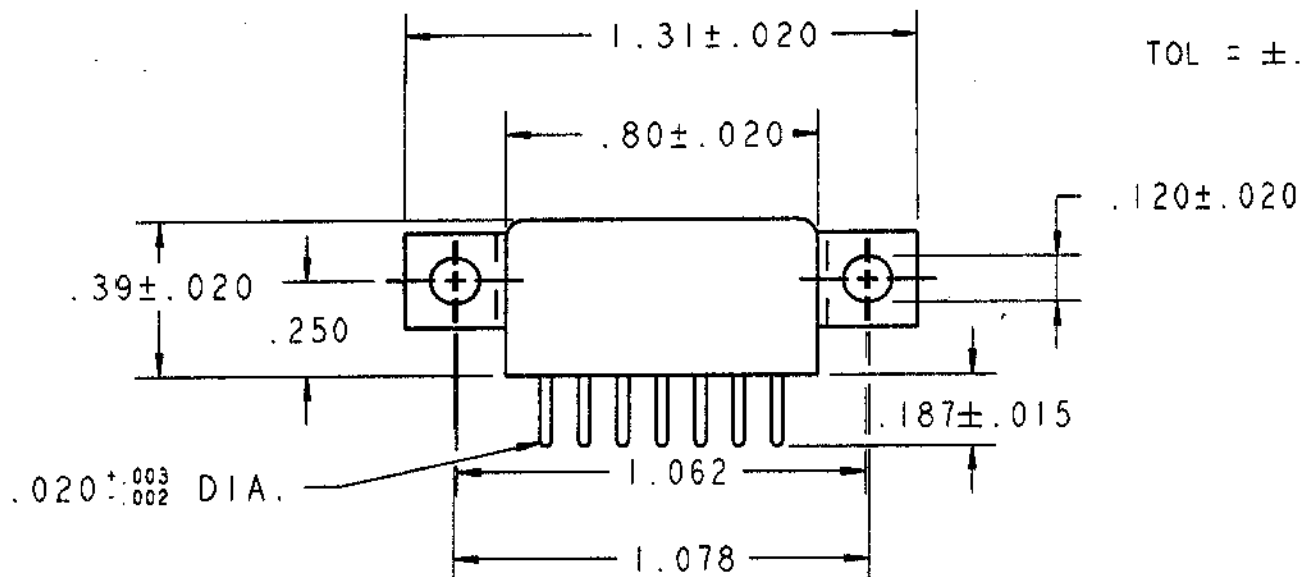

REV. 0

DCO 64109


COIL: @ 25°C
 RESISTANCE 390 OHMS ±10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.0 VDC
 MUST RELEASE 10.1 VDC MAX, 1.84 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 15 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 7 MS MAX.
 (INCLUDING BOUNCE)

CUSTOMER DATA SHEET

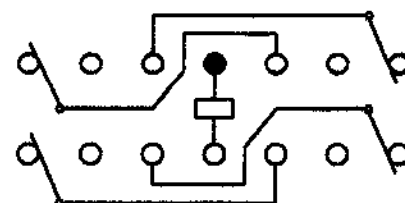

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
 2 AMP 28 VDC RESISTIVE
 100,000 OPERATIONS

DR. PBB 7/20/01 CK. 7/20/01

CII Technologies
 advanced control electronic solutions

CUST. QPL
 CUST. NO. M39016/40-025 REV.

"SR" RELAY

SR-7625