

REV. 2

DCO 63333

COIL: @ 25°C	
RESISTANCE	390 OHMS ± 10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.0 VDC @ 25°C
MUST RELEASE	1.4 VDC @ 25°C

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 15 g's


SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 5 MS MAX.

BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

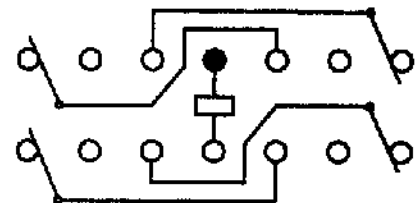

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO

2 AMP 28 VDC RESISTIVE

DR. R.B. 4/5/93

CK. TLG 10-24-00

**CCI Technologies**  
advanced control electronic solutions

CUST. C. I. I. STD.

CUST. NO. \_\_\_\_\_ REV. \_\_\_\_\_

"SR" RELAY

SRAW-4C-24B