



940 Kabelklemmung Krone


TE Teile Nr.: 50-0335-000-P00
IC Ref. Nr.: 50.335.00

Technische Daten

Temperaturbereich -20 °C bis 130 °C
Kabelklemmbereich $\varnothing 16,5$ mm - $\varnothing 25,0$ mm

Werkstoffe

Klemmstück PA 66/ V0, schwarz
Dichtungen FKM

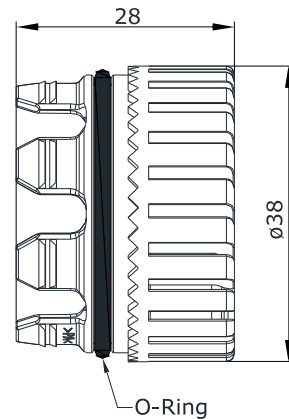

Hauptabmessungen
Kabelklemmung





940 Cable Clamp Crown

TE part number: 50-0335-000-P00
IC reference number: 50.335.00

Technical Data


temperature range
clamping range

-20 °C to 130 °C
ø16.5 mm - ø25.0 mm

Material

clamp piece
seals

PA 66/ V0, black
FKM

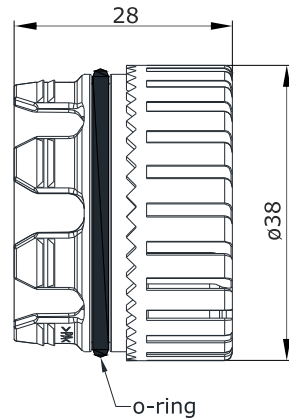

Main Dimensions
cable clamp

