

Figure 1

 
1. INTRODUCTION

This instruction sheet provides installation procedures for the Cat5e 6-Port Connectivity Module 1479700-1 which is used in the

AMP NETCONNECT HOME NET-WORKS media convergence centers (MCC).

The Structured Cabling System is recommended to be installed in accordance with the ANSI TIA/EIA-570-B Residential Telecommunications Cabling Standard. Refer to that publication for technical specifications on wiring and cables.

To obtain information on AMP NETCONNECT* products, call PRODUCT INFORMATION at the number at the bottom of this page, or visit the AMP NETCONNECT website at www.ampnetconnect.com.



All numerical values are in metric units [with U.S. customary units in brackets]. Figures and illustrations are for reference only and are not drawn to scale.

AMP NETCONNECT logo is a trademark of Tyco Electronics.

2. DESCRIPTION

Basic terms and features of kit components are provided in Figure 1. The connectivity module is shipped assembled into the plastic interface housing. The 110Connect ID label is supplied loose.

3. INSTALLATION

The Cat5e Connectivity Module may be mounted into the Front-Loadable 18-Port Panel (part number 1479699-1), or other panels with openings of the same dimensions. Cat5e cabling shall be terminated to the connectivity module as shown in Figure 2.

It is recommended that T568A wiring pattern be used for residential installations.

4. REVISION SUMMARY

The following changes apply to this revision:

- Updated document to corporate requirements

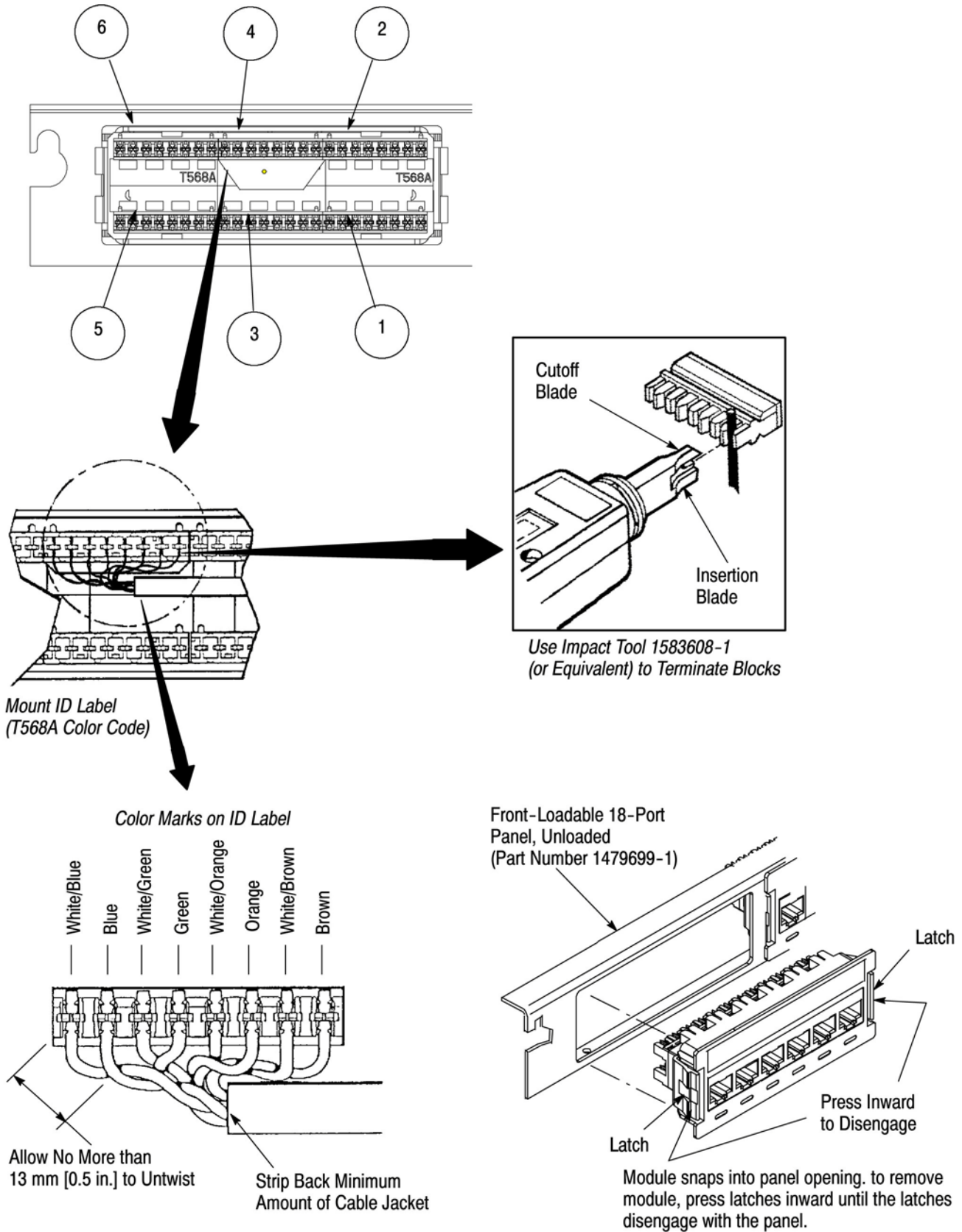


Figure 2