


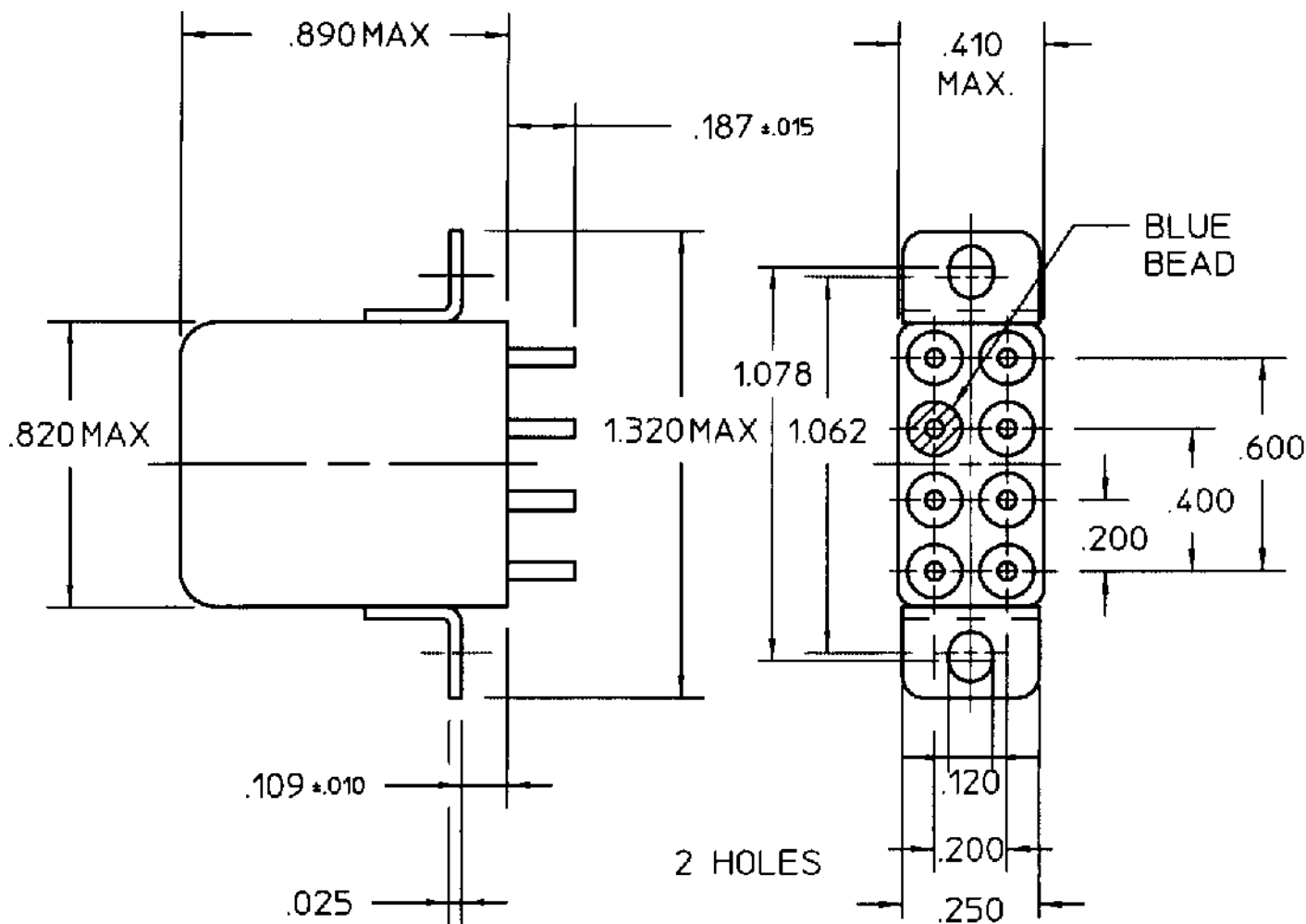


REV. 0
DCO 16226

COIL: @ 25°C
RESISTANCE 620 OHMS ± 10%
NOMINAL VOLTAGE 26.5 VDC
MUST OPERATE 13.0 VDC
MUST RELEASE 1.9 VDC

ENVIRONMENT:
VIBRATION 10 CPS TO 2000 CPS @ 20 g's
SHOCK 100 g's 6 ± 1 MS. DURATION
TEMPERATURE -65 °C TO +125 °C
NOTES: OPERATE & RELEASE 5 MS MAX.
CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

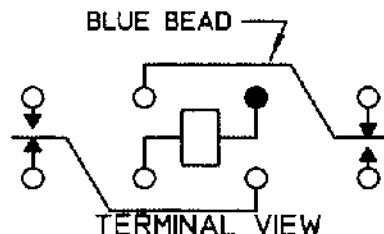

CONTACT RATING: 3 AMPS 28 VDC
RESISTIVE 100,000 OPERATIONS

DR. PBB 4-27-00 CK. 1/27/00

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. CII STD
CUST. NO. REV.
'AR' RELAY

ARBW-2C-24B