



intercontec
products

Kontaktbuchse 10 mm Lamelle

Einsatzbereich: - 958 Stecker
Crimp 35 mm²

TE Teile Nr.: 60-0104-023-P00
IC Ref. Nr.: 60.104.23

Elektrische Werte

Bemessungsstrom
Durchgangswiderstand

max. 132 A*
< 90 µOhm

Werkstoff

Kontakt
Lamellenfeder

Messing, versilbert
CuBe, versilbert

Anschluss

Anschlussart/-bereich
max. Litzenaußendurchmesser
Abisolierlänge
Crimpeinstellungen

Crimp/ 35 mm²
ø14,8 mm
17 mm
sind individuell zu wählen

Mechanische Werte


Steckzyklen

500

Werkzeuge (nicht im Lieferumfang enthalten)

Akku Crimpzange

TE Teile Nr.: C0-0207-000-000
IC Ref. Nr.: C0.207.00

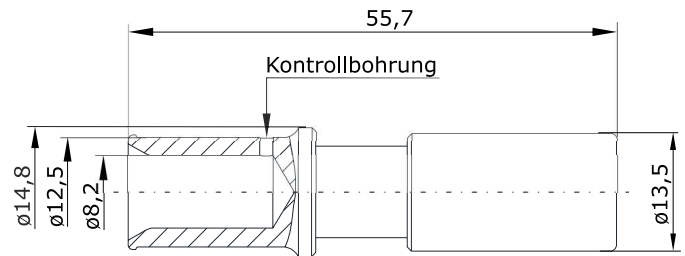

Hauptabmessungen

Kontaktbuchse





intercontec
products

Contact Socket 10 mm Lamella

for: - 958 Plug
crimp 35 mm²

TE part number: 60-0104-023-P00
IC reference number: 60.104.23

Electrical Data

rated current
contact resistance

max. 132 A*
< 90 µOhm

Material

contact
lamella spring

brass, silver plated
CuBe, silver plated

Termination

cross-section
max. outer wire diameter
stripping length
crimp settings

crimp/ 35 mm²
ø14.8 mm
17 mm
select individually


Mechanical Data

mating cycles

500

Tools (not part of product contents)
battery crimping tool

TE part no.: C0-0207-000-000
IC ref. no.: C0.207.00

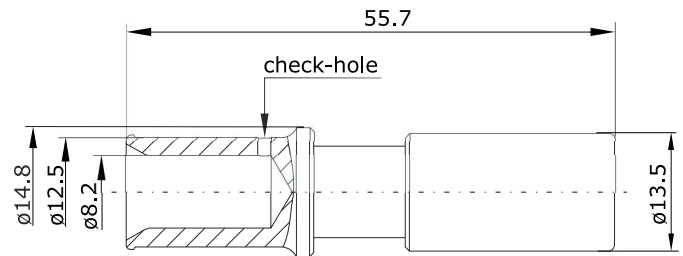

Main Dimensions
contact socket

