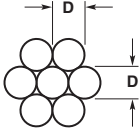
 
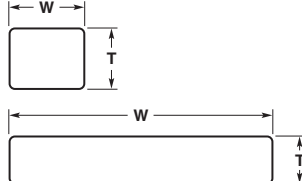


Wire Calculations and Instructions

How to Compute Circular Mil Area of Various Wire Shapes

	U.S. Customary Dimensions	Metric Dimensions
Stranded Wire AWG  Number of Strands	Use Chart 1. Read circular mil area directly from table. Alternate Method Multiply the diameter of one strand (in mils) by itself, and then multiply the result by the total number of strands. $CMA = D^2 \times N$	Use Chart 1. Read circular mil area directly from table. Alternate Method Multiply the diameter of one strand in millimeters by itself, and then by the number of strands, and then by 1500.003. $CMA = D^2 \times N \times 1550.003$
Round Solid Wire AWG 	Use chart 1 or 2. Read circular mil area directly from table. Alternate Method Multiply the diameter in mils by itself. $CMA = D^2$	Use chart 1 or 2. Read circular mil area directly from table. Alternate Method Multiply the diameter in millimeters by itself by 1550.003. $CMA = D^2 \times 1550.003$
Square or Rectangular Wire 	Multiply the width of the wire cross section in mils by the thickness of the wire cross section in mils by 1.2732 and subtract the radius factor included below. $CMA = W \times T \times 1.2732 - \text{radius factor}$	Multiply the width of the wire cross section in millimeters by the thickness in millimeters by 1973.525 and subtract the radius factor included below. $CMA = W \times T \times 1973.525 - \text{radius factor}$

Conversion Table

To Convert From	To	Multiply By
CMA	mm ²	0.0005067075
CMA	in ²	0.0000007854
mm ²	in ²	0.0015500030
mm ²	CMA	1973.525

Radius Factor, U.S. Customary

Radius (in.)	Radius Factor To Subtract (CMA)
.010	110
.012	158
.016	280
.020	438
.026	740
.032	1121
.040	1752
.063	4346
.940	9675

Radius Factor, Metric

Radius (mm)	Radius Factor To Subtract (CMA)
0.25	106
0.30	153
0.35	208
0.40	272
0.50	424
0.60	611
0.80	1086
1.20	2444
0.94	9675

How to Compute Circular Mil Area of Various Wire Shapes (Continued)

**Circular Mil Area (CMA) /
Nominal Wire Sizes**

CMA	Normal Wire Size		No.	Strands		Approximate Conductor Diameter	
	AWG	mm ²		Diameter		Inch	mm
				Inch	mm		
4.0	44	0.002	1	.00195	0.050	.002	0.051
16.0	38	0.008	1	.0040	0.102	.004	0.102
64.0	32	0.032	1	.0080	0.203	.008	0.203
175.0	28	0.089	7	.0050	0.127	.015	0.381
388	24	0.197	1	.0197	0.500	.020	0.508
397	24	0.201	10	.0063	0.160	.023	0.584
400	24	0.203	16	.0050	0.127	.023	0.584
400	24	0.203	4	.0100	0.254	.023	0.584
403	24	0.204	8	.0071	0.180	.023	0.584
634	22	0.321	8	.0089	0.226	.029	0.737
635	22	0.322	16	.0063	0.160	.029	0.737
640	22	0.324	10	.0080	0.203	.029	0.737
640	22	0.324	1	.0253	0.643	.025	0.635
992	20	0.503	1	.0315	0.800	.032	0.813
1000	20	0.507	10	.0100	0.254	.038	0.965
1008	20	0.511	20	.0071	0.180	.039	0.991
1024	20	0.519	16	.0080	0.203	.039	0.991
1600	18	0.811	16	.0100	0.254	.049	1.245
1608	18	0.815	19	.0092	0.234	.049	1.245
1617	18	0.819	7	.0152	0.386	.042	1.067
1624	18	0.823	1	.0403	1.024	.040	1.016
2521	16	1.277	50	.0071	0.180	.059	1.499
2540	16	1.287	16	.0126	0.320	.059	1.499
2581	16	1.308	1	.0508	1.290	.051	1.295
2800	16	1.419	7	.0200	0.508	.061	1.549
3831	14	1.941	19	.0142	0.361	.076	1.930
4099	14	2.077	7	.0242	0.615	.076	1.930
4109	14	2.082	1	.0641	1.628	.064	1.626
6503	12	3.295	19	.0185	0.470	.092	2.337
6512	12	3.300	7	.0305	0.775	.086	2.184
6529	12	3.308	1	.0808	2.052	.081	2.057
9072	10	4.597	7	.0360	0.914	.096	2.438
10080	10	5.108	1	.1004	2.550	.100	2.540
10404	10	5.272	19	.0234	0.594	.117	2.972
16512	8	8	1	.1285	3.260	.129	3.260
16533	8	8	7	.0486	1.230	.146	3.710
16535	8	8	19	.0295	0.750	.148	3.760
262218	6	13	7	.0612	1.550	.184	4.670
26244	6	13	1	.1620	4.110	.162	4.110
26292	6	15	19	.0372	0.940	.202	5.130
41616	4	21	1	.2040	5.182	.204	5.180
41718	4	21	7	.0772	1.961	.232	5.890
41792	4	21	19	.0469	1.191	.226	5.740
95509	0	50	19	.0709	1.800	.354	9.000
97610	0	50	396	.0157	0.400	.406	10.300
98409	0	50	702	.0118	0.300	.370	9.400

Part Number Index

Note: This index lists all cataloged parts by base no. only. Complete part nos. (with prefixes and/or suffixes) are shown on the page(s) indicated.

Part No.	Page
55323	170
55556	169
55557	169
55558	170
55673	169
58490	119
58491	119
58492	119
58493	119
60151	91
62531	220
66084	91
68344	145
104501	201
104502	201
104729	201
104742	201
120591	233
120943	55
120943	55
120953	39, 55
120954	53
120954	53
120955	53
120956	53
120957	53
120958	53
146845	232
167892	171, 172
170221	87
170222	87
170286	87
170289	87
170311	87, 95
170312	95
170313	87, 95
170314	95
170484	87, 95
170485	87, 95
172059	94
172061	94
172063	94
172624	94
172653	93
173032	94
173977	100
179227	101
179228	101
179316	98
179317	98
179321	98
179322	98
179518	101
179609	101
179694	100
192000	134
192001	134
192002	134

Part No.	Page
192004	134
192007	134, 139
192008	134, 139
192013	136
192033	136
192038	135, 137
192039	135, 139
192040	137
192041	135, 137
192042	135, 139
192043	137
192044	135, 137, 138
192045	135, 139
192046	138
192047	138
192048	135, 139
192059	129
192061	129
192085	129
192129	129
192211	129
192244	129
192271	129
192293	129
192447	130
193673	132
193837	131
194257	133
194305	133
208211	214
208697	220
208979	220
213598	221
213647	201
213727	221
213815	170
213816	170
213878	220
216843	171, 172
216905	171, 172
216906	170, 172
216907	170, 172
216926	171, 172
223041	56
223956	58
223969	58
223982	58
292180	97
292181	99
292182	99
292183	97
292184	97
292185	98
292186	97
292187	97
292189	97
292190	97
292192	97
292491	18
292495	18
292499	21
338429	171

Part No.	Page
343347	90
343348	90
343371	89, 90, 91
343404	88
343886	89
343887	89
530553	213
556135	119
556136	119
556137	118
556879	123
556880	123, 124
556881	121
556882	122
556883	123, 124
557313	118
557640	118
558084	121
558574	121
567256	119
567403	119
583204	89, 90, 91
583294	89, 90
583361	91
583555	91
583989	91
583990	89, 91
583991	91
647691	152
647692	152
647719	152
647720	152
647721	152
647722	152
647737	152
647747	151
647754	144, 145
647755	144, 145
647756	144, 145
647840	151
647845	143
647877	143, 144, 145
647878	143, 144, 145
647879	143, 144, 145
647892	143
647893	143
650025	186, 187
680308	112
680447	119
680449	119
748572	210, 213
765191	209
765204	210
765206	210
765208	213
765209	214, 215
765224	214, 215
765225	208
765228	208
765229	208
765238	214
765241	216

Part No.	Page
765242	216
765247	214, 215
765248	215
765249	213
765250	214
765251	215
765261	214, 215
765265	213
765271	210
765276	212
765277	212
765278	212
765295	212
765296	212
765311	212
765449	211
765450	211
765451	211
765478	209
765527	213
765527	213
765528	209, 214, 215
765529	209, 215
765530	209, 214
765608	213
766090	216
766510	213
766569	209
787328	232
787439	232
787613	232
787614	232
787615	232
788109	119
788110	119
794144	107
794145	107
794149	107
794150	107
794152	107
794153	107
794156	107
794318	107
794319	107
794322	107
794576	112
796136	233
796285	220
927829	103
927831	103
927837	103
927840	103
963709	103
1123684	230
1123688	230
1123822	230
1318574	230
1385663	145
1385664	145
1410270	52
1410271	52
1410278	52

Part Number Index (Continued)

Part No.	Page	Part No.	Page	Part No.	Page	Part No.	Page
1410279	52	1604001	146	1648162	70	1651929	191, 192
1410297	59	1604002	146	1648163	70	1674231	230
1410465	59	1604037	148	1648168	70	1717445	230
1410546	59	1604038	148, 149	1648183	73	1717458	228
1410548	59	1604039	148, 149	1648186	73	1717478	230
1410710	59	1604040	148, 149	1648203	69	1717620	230
1410714	59	1604041	148, 149	1648204	69	1734178	233
1410773	59	1604042	148	1648205	69	1734894	235
1410956	59	1604043	148	1648206	69	1744041	142
1410962	59	1604044	148	1648207	69	1744042	142
1410963	59	1604045	148	1648208	69	1744077	151
1445715	145	1604050	150	1648211	78	1744090	152
1445716	145	1604051	150	1648212	78	1747602	230
1445729	151	1604052	150	1648325	81	1747785	228
1445762	151	1604053	150	1648382	81	1747786	228
1445763	151	1604054	150	1648384	81	1761122	188
1445886	151, 152	1604055	150	1648387	81	1761259	190
1445957	142	1604056	150	1648461	156	1761347	188
1445959	151	1604057	150	1648462	156	1761419	21
1445960	151	1604058	150	1648463	156	1761421	27
1445962	142	1604059	150	1648464	156	1761426	184
1445994	147	1604060	150	1648465	157	1761500	183
1445995	146, 147	1604062	149	1648466	156	1761786	184
1445996	146, 147	1604072	152	1648467	156	1761819	21
1445997	146, 147	1604112	142	1648468	156	1761879	183
1445998	147	1604113	142	1648469	156	1766056	32
1445999	147	1604121	152	1648470	157	1766057	32
1446000	147	1604342	144	1648473	157	1766157	47
1469265	58	1604395	149	1648482	157	1766160	47
1469269	58	1604396	149	1648505	157	1766161	47
1469372	58	1604397	149	1648548	74	1766163	47
1469373	58	1604398	149	1648549	74	1766192	80
1469374	58	1604433	143, 144, 145	1648552	73	1766193	80
1469387	58	1612503	230	1648568	77	1766194	80
1469388	58	1612504	230	1648574	74	1766195	80
1469491	59	1612898	228	1648575	74	1766196	80
1469492	59	1612901	228	1648578	73	1766197	80
1469606	109	1612962	228	1648596	77	1766198	80
1469609	109	1612963	228	1650060	80	1766199	80
1469610	109	1612964	228	1650065	80	1766222	80
1469910	111	1643279	167	1650073	80	1766223	80
1469920	37	1643903	196	1650074	80	1766230	81
1469921	37	1643906	195	1650106	65	1766231	81
1469922	37	1645498	54	1650153	80	1766232	80
1470390	234	1645499	54	1650155	80	1766245	80
1489127	84	1645545	58	1650156	80	1766249	80
1489128	84	1648110	69	1650158	80	1766250	80
1489701	84	1648111	69	1650161	80	1766262	80
1489715	84	1648112	69	1650162	80	1766263	80
1600236	27	1648115	69	1650226	80	1766268	81
1600238	27	1648116	69	1650283	80	1766269	81
1600606	21	1648117	69	1650399	65	1766270	81
1600636	21	1648127	77	1650401	65	1766274	81
1600788	22	1648128	77	1650402	65	1766275	81
1600798	22	1648132	72	1650469	159	1766276	81
1600814	27	1648133	72	1650589	65	1766283	80
1600820	27	1648134	72	1651003	165	1766308	192
1600902	24, 109	1648135	72	1651202	79	1766336	188, 191, 192
1600903	23	1648151	71	1651203	79	1766436	188, 191, 192
1600914	21, 24	1648152	71	1651766	167	1766442	191, 192
1600960	23	1648156	71	1651826	188, 191, 192	1766443	191, 192
1600961	23	1648157	71	1651864	191, 192	1766447	76

Part Number Index (Continued)

Part No.	Page	Part No.	Page	Part No.	Page	Part No.	Page
1766448	76	1926273	39	5536565	56	6450130	13, 18, 21
1766484	165, 166	1926671	197	5536600	56	6450131	13
1766500	61	1926720	35	5536603	56	6450132	13, 18
1766501	61	1926721	35	5536607	57	6450140	12
1766502	61	1926732	35	5536613	57	6450142	12
1766503	61	1926733	35	5536614	57	6450150	12
1766600	165	1926785	192	5536620	56	6450151	12
1766663	48	1934017	111	5536623	56	6450152	12
1766685	192	1934142	111	5536625	56	6450160	12, 27
1766735	188, 192	1934143	111	5536628	56	6450161	12
1766811	81	1934144	111	5536642	56	6450163	12
1766812	80	1934145	111	5536642	56	6450170	12, 27
1766815	47	1934182	113	5536649	57	6450172	12
1766816	47	1934183	113	5645384	187	6450173	12, 27
1766817	47	1934184	112	5646954	53	6450178	18
1766818	80	1934185	112	5646955	53	6450230	13
1766819	81	1934193	113	5646956	53	6450231	13
1766821	80	1934988	58	5646957	53	6450330	13, 18, 21
1766829	159	1982257	54	5646958	53	6450503	13
1775069	235	1982260	54	5650118	187	6450523	13
1775485	233	1982295	104	5650118	187	6450540	12, 27
1775529	235	1982299	104	5787090	229	6450541	12
1775637	235	1982530	199	5787141	231	6450543	12, 27
1775638	234	1982995	199	5787142	231	6450550	12, 27
1775639	234	2007088	183	5787246	231	6450551	12
1775640	222	2042274	104	5787252	229	6450553	12
1775641	222	2057372	183	5787253	229	6450558	18
1775642	222	2085181	48	5787334	231	6450560	12
1775643	222	5055323	170	5787418	231	6450570	12
1820539	204	5055556	169	5787419	231	6450578	18
1827501	228	5055557	169	5787421	231	6450622	18
1827654	228	5055558	170	5787422	231	6450668	18
1827684	228	5055673	169	5787424	231	6450740	27
1827685	228	5120913	58	5787428	231	6450810	16
1852467	112, 113	5145089	187	5787430	231	6450820	16
1852468	112, 113	5145459	193	5787441	231	6450830	16
1852469	113	5146877	229	5787443	231	6450831	16
1857147	204	5167892	172	5787444	231	6450840	16
1857178	166	5172068	94	5787446	231	6450850	16
1857523	165, 166	5172069	94	5787526	229	6450860	16
1857547	165, 166, 204	5172070	94	5787531	229	6450870	16
1857561	204	5172625	94	5787590	232	6450871	16
1857988	58	5173033	94	5787802	232	6450880	16
1888132	18	5176916	86	5794172	106	6469602	109
1888179	18	5213815	170	5794173	106	6473451	230
1888803	61	5213816	170	5794176	106	6473539	230
1888804	61	5221980	18	5796078	231	6489165	188, 193
1888946	184	5221981	18	6123738	230	6489649	193
1903977	53	5223092	57	6123978	230	6489651	188
1903978	55	5223093	57	6123981	230	6489930	188
1926024	192	5223955	39, 55	6123987	230	6600303	13, 21
1926088	177	5223957	58	6318430	230	6600310	18
1926155	192	5223961	53	6318573	230	6600323	13
1926223	39	5223963	53	6318792	230	6600330	13, 21
1926224	39	5223979	58	6318977	230	6600333	13, 21
1926225	39	5223985	58	6339488	233	6600380	22
1926226	39	5223986	58	6376042	230	6600383	22
1926227	39	5223995	55	6450120	13, 21	6600390	22
1926228	39	5530843	186	6450121	13	6600393	22
1926229	39	5531216	24	6450123	13, 21	6643219	46
1926271	39	5531224	24	6450128	22	6643220	49
1926272	39	5532600	187	6450129	22	6643222	49

Part Number Index (Continued)

Part No.	Page	Part No.	Page	Part No.	Page	Part No.	Page
6643223	49	6643449	46	6648418	82	6651668	32
6643227	49	6643450	46	6648419	82	6651669	32
6643228	49	6643451	46	6648420	82	6651670	32
6643229	49	6643460	179	6648428	82	6651671	32
6643232	46	6646465	43	6648429	82	6651672	32
6643248	47	6646597	43	6648430	82	6651673	32
6643252	47	6646722	43	6648431	82	6651711	192
6643253	47	6648167	70	6648434	82	6651712	192
6643264	46	6648221	165, 166	6648435	82	6651742	32
6643266	46	6648222	165, 166	6648454	158	6651743	32
6643269	46	6648223	165, 166	6648457	158	6651810	78
6643271	46	6648224	165, 166	6648476	158	6766014	76
6643272	46	6648226	165, 166	6648499	158	6766015	76
6643273	46	6648228	165, 166	6648508	158	6766439	46
6643274	46	6648234	165, 166	6648515	158	6766440	46
6643275	46	6648235	165, 166	6650380	177	6766441	46
6643276	46	6648236	165, 166	6650383	177	6766615	78
6643281	46	6648237	165, 166	6650384	177	60DB8	225
6643283	46	6648238	165, 166	6650494	178	60DB8	226
6643431	46	6648239	165, 166	6650534	178	60DBF8	225
6643432	46	6648251	159	6650679	157	60DBF8	226
6643433	46	6648252	159	6650680	157	60DBJ8	225
6643434	46	6648253	159	6650785	46	60DBJ8	226
6643435	46	6648254	159	6651170	177	60DBP	225
6643436	46	6648259	159	6651193	178	60DBPL	225
6643437	46	6648263	159	6651204	79	60DBPL1	225
6643438	46	6648317	47, 82	6651205	79	60DBPL3	225
6643439	46	6648318	81	6651214	178	60DBPL9	225
6643440	46	6648319	81	6651290	179	60DBR	225
6643441	46	6648335	82	6651331	177	60DBRL	225
6643442	46	6648374	81	6651380	32	60DBRL1	225
6643443	46	6648383	81	6651381	32	60DBRL3	225
6643444	46	6648400	82	6651457	75	60DBX	225
6643445	46	6648405	82	6651458	75	60DBX8	225
6643446	46	6648416	82	6651493	75	60DBX8	226
6643447	46	6648417	82	6651494	75		

Engineering Notes



Americas

Argentina – Buenos Aires
Phone: +54-11-4733-2200
Fax: +54-11-4733-2211

Brasil – São Paulo
Phone: +55-11-2103-6000
Fax: +55-11-2103-6030

Chile – Santiago
Phone: +56-2-345-0361
Fax: +56-2-223-1477

Canada – Toronto
Phone: +905-475-6222
Fax: +905-474-5520
Product Information Center:
Phone: +905-470-4425
Fax: +905-474-5525

Colombia – Bogota
Phone: +57-1-319-8959
Fax: +57-1-319-8960

Mexico – Mexico City
Phone: +52-55-1106-0800
+01-800-733-8926
Fax: +52-55-1106-0901

For Latin/South American Countries not shown
Phone: +54-11-4733-2015
Fax: +54-11-4733-2083

United States
Harrisburg, PA
Phone: +1-717-564-0100
Fax: +1-717-986-7575
Product Information Center:
Phone: +1-800-522-6752
Fax: +1-717-986-7575
Troy, MI
Phone: +1-248-273-3359
Fax: +1-248-273-3322

Asia/Pacific

Australia – Sydney
Phone: +61-2-9554-2600
Fax: +61-2-9502-2556
Product Information Center:
Phone: +61-2-9840-8200
Fax: +61-2-9634-6188

India – Bangalore
Phone: +91-80-285-40800
Fax: +91-80-285-40820

Indonesia – Jakarta
Phone: +65-6482-0311
Fax: +65-6482-1012

Japan – Kawasaki, Kanagawa
Phone: +81-44-844-8111
Fax: +81-44-812-3207
Product Information Center:
Phone: +81-44-844-8013
Fax: +81-44-812-3200

Korea – Seoul
Phone: +82-2-3415-4500
Fax: +82-2-3486-3810

Malaysia – Selangor
Phone: +60-3-7805-3055
Fax: +60-3-7805-3066

New Zealand – Auckland
Phone: +64-9-634-4580
Fax: +64-9-634-4586

Philippines – Makati City
Phone: +632-848-0171
Fax: +632-867-8661

People's Republic of China
Hong Kong
Phone: +852-2735-1628
Fax: +852-2735-0243
Shanghai
Phone: +86-21-2407-1588
Fax: +86-21-2407-1599

Singapore – Singapore
Phone: +65-6482-0311
Fax: +65-6482-1012

Taiwan – Taipei
Phone: +886-2-8768-2788
Fax: +886-2-8768-2268

Thailand – Bangkok
Phone: +66-2-955-0500
Fax: +66-2-955-0505

Vietnam – Ho Chi Minh City
Phone: +84-8-930-5546
Fax: +84-8-930-3443

Europe/Middle East/Africa

Austria – Vienna
Phone: +43-1-905-60-0
Fax: +43-1-905-60-1333
Product Information Center:
Phone: +43-1-905-60-1249
Fax: +43-1-905-60-1251

Belarus – Minsk
Phone: +375 17 237 47 94
Fax: +375 17 237 47 94

Belgium – Kessel-Lo
Phone: +32-16-352-300
Fax: +32-16-352-355

Bulgaria – Sofia
Phone: +359-2-971-2152
Fax: +359-2-971-2153

Czech Republic and Slovakia
Czech Republic – Kurim
Phone: +420-541-162-111
Fax: +420-541-162-223
Product Information Center:
Phone: +420-541-162-113
Fax: +420-541-162-132

Denmark – Glostrup
Phone: +45-43-48-04-00
Fax: +45-43-44-14-14

Egypt – Cairo
Phone: +202-419-2334
Fax: +202-417-7647

Estonia – Tartu
Phone: +372-5138-274
Fax: +372-7400-779

Finland – Helsinki
Phone: +358-95-12-34-20
Fax: +358-95-12-34-250

France – Cergy-Pontoise Cedex
Phone: +33-1-3420-8888
Fax: +33-1-3420-8600
Product Information Center:
Phone: +33-1-3420-8686
Fax: +33-1-3420-8623

France Export Divisions –
Cergy-Pontoise Cedex
Phone: +33-1-3420-8804
Fax: +33-1-3420-8699

Germany – Bensheim
Phone: +49-6251-133-0
Fax: +49-6251-133-1600
Product Information Center:
Phone: +49-6251-133-1999
Fax: +49-6251-133-1988

Greece – Athens
Phone: +30-210-9370-396/397
Fax: +30-210-9370-655

Hungary – Budapest
Phone: +36-1-289-1000
Fax: +36-1-289-1010
Product Information Center:
Phone: +36-1-289-1016
Fax: +36-1-289-1017

Ireland – Dublin
Phone: +353-1-866-5612
Fax: +353-1-866-5714

Israel – Petach-Tikva
Phone: +972-3-929-0999
Fax: +972-3-919-1088

Italy – Collegno (Torino)
Phone: +39-011-4012-111
Fax: +39-011-4031-116
Product Information Center:
Phone: +39-011-4012-428
Fax: +39-011-40-287-428

Lithuania and Latvia
Lithuania – Vilnius
Phone: +370-5-213-1402
Fax: +370-5-213-1403
Product Information Center:
Phone: +370-5-211-3016
Fax: +370-5-213-1403

Netherlands – 's-Hertogenbosch
Phone: +31-73-6246-246
Fax: +31-73-6212-365
Product Information Center:
Phone: +31-73-6246-999
Fax: +31-73-6246-998

Norway – Nesbru
Phone: +47-66-77-88-50
Fax: +47-66-77-88-55

Poland – Warsaw
Phone: +48-22-4576-700
Fax: +48-22-4576-720
Product Information Center:
Phone: +48-22-4576-704
Fax: +48-22-4576-720

Romania – Bucharest
Phone: +40-21-311-3479/3596
Fax: +40-21-312-0574

Russia – Moscow
Phone: +7-495-790-7902
Fax: +7-495-721-1893
Product Information Center:
Phone: +7-495-790-7902-404
Fax: +7-495-790-7902-401

Russia – St. Petersburg
Phone: +7-812-718-8192
Fax: +7-812-718-8193

Slovenia – Ljubljana
Phone: +386-1561-3270
Fax: +386-1561-3240

South Africa – Port Elizabeth
Phone: +27-41-503-4500
Fax: +27-41-581-0440

Spain – Barcelona
Phone: +34-93-291-0330
Fax: +34-93-201-7879

Sweden – Upplands Väsby
Phone: +46-8-50-72-50-00
Fax: +46-8-50-72-50-01

Switzerland – Steinach
Phone: +41-71-447-0447
Fax: +41-71-447-0444

Turkey – Istanbul
Phone: +90-212-281-8181/2/3
+90-212-282-5130/5430
Fax: +90-212-281-8184

Ukraine – Kiev
Phone: +380-44-206-2265
Fax: +380-44-206-2264
Product Information Center:
Phone: +380-44-206-2265
Fax: +380-44-206-2264

United Kingdom –
Stanmore, Middlesex
Phone: +44-8706-080208
Fax: +44-208-954-6234
Product Information Center:
Freephone (UK only):
0800-267-666
Phone: +44-8706-080208
Fax: +44-208-420-8095