
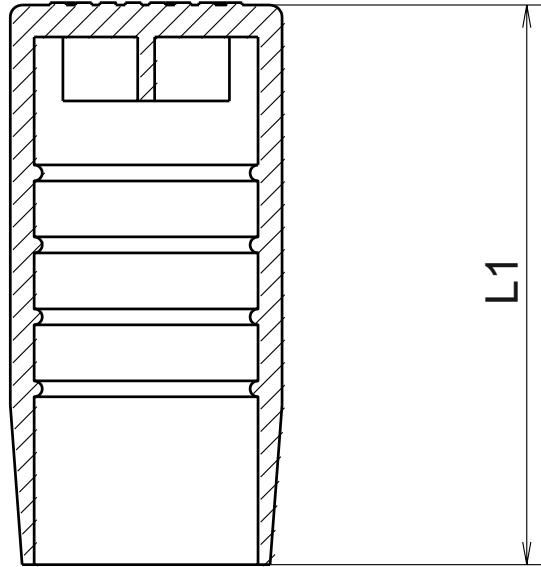



Copying of the document and giving it to other and the use or communication of the contents thereof, are forbidden without express authority. Offenders are liable to the payment of damages. All rights are reserved in the event of the grant of a patent or the registration of a utility model or design.

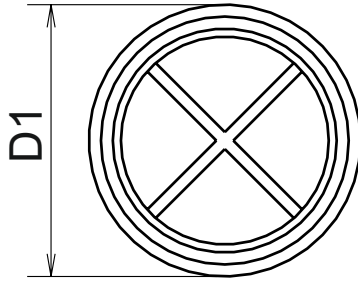

Description	Cable Diameter [mm]	Application Range* [mm ²]	L1 [mm]	D1 [mm]	Part Number
GURO-CEC-8/12	8 - 12	3 - 4 x 1,5	50	15	CN1960-000
GURO-CEC-11/16	11 - 16	4 - 5 x 1,5 - 2,5	55	18	300158-000
GURO-CEC-16/22	16 - 22	4 - 5 x 4 - 16	60	20	890196-000
GURO-CEC-20/26	20 - 26	4 - 5 x 10 - 16 / 4 x 25	70	24	926542-000
GURO-CEC-23/30	23 - 30	4 - 5 x 25 - 35 / 4 x 50	70	27	096456-000
GURO-CEC-24/34	24 - 34	4 - 5 x 25 - 35 / 4 x 50	70	30	398064-000
GURO-CEC-30/38	30 - 38	4 x 50 - 70	70	34	548978-000
GURO-CEC-38/48	38 - 48	4 x 95 - 120	80	42	540908-000
GURO-CEC-44/54	44 - 54	4 x 120 - 185	90	51	625720-000

* Application Range should be seen as a guideline only, relevant specification is the cable diameter.

Customer Drawing							
				2020	DATE	NAME	GURO-CEC
				DRAWN	21.01.	Beckmann	
				CHECKED			
						Tyco Electronics Raychem GmbH Werk Berlin	CD-GURO-CEC
REV.	MODIFICATION	DATE	N.	CAD NO.:		DRAWING NO.:	
						REPLACEMENT FOR:	