


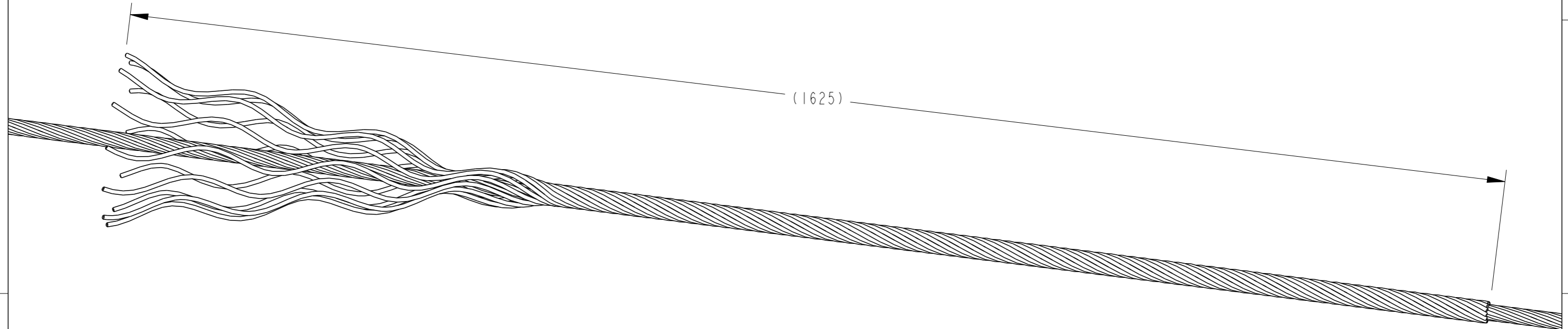

ARMOUR RODS

CATALOGUE NUMBER: NAA1605-1665 SUITS CONDUCTOR

STRANDING	COND. TYPE	DIAMETER	FITTING LAY
19/3.25	AAC/AAAC	16.25	RIGHT HAND
19/0.128	AAC/AAAC	16.25	RIGHT HAND
30/7/0.093	ASCR	16.05	RIGHT HAND



BOX LABEL

P/N: NAA1605-1665
ID:
DESCRIPTION:
 NON-TENSION ALUMINIUM ARMOUR RODS (NAA) FITTING
 19/3.25 AAC/AAAC
 19/0.128 AAC/AAAC
 30/7/0.093 ASCR
RANGE: 16.05 - 16.65
COLOUR-CODE: ORANGE
QTY: 15 **WEIGHT:** **BATCH:**

PRODUCT LABEL

NAA1605-1665
 19/3.25 AAC/AAAC
 19/0.128 AAC/AAAC
 30/7/0.093 ASCR

WEIGHT: 1.05kg
BATCH NO:
MONTH/YEAR:

TECHNICAL SPECIFICATIONS:

CATALOGUE NUMBER: NAA1605-1665
DESCRIPTION: NON-TENSION ALUMINIUM ARMOUR RODS (NAA) FITTING
MATERIAL: ALUMINIUM ALLOY
NUMBER OF RODS: 12
ROD DIAMETER: 4.88mm
OVERAL LENGTH: 1625mm
END FINISH: BALLENDDED
FITTING LAY DIRECTION: RIGHT HAND
COLOUR CODED: ORANGE
RODS ARE LABELED, BUNDLED IN A SET AND TAPED AT BOTH ENDS.

LOC								IMPLIED NOTES BURRS AND SHARP EDGES REMOVED SCREW THREADS ARE TO AS 1275 DO NOT WORK TO DIMS MARKED REF SURFACE FINISH 6.3 U.N.O. DIMS ARE IN mm. DO NOT SCALE	IMPLIED TOLERANCES HOLE DIA AND LOCATIONS. ±0.5mm. DIMENSIONS UP TO 30mm. ±1.5mm. DIMENSIONS OVER 30mm. ±5%. UP TO A MAX OF ±5mm. ANGULAR DIMENSIONS. ±5°.	TCPN - PART Alias UTX/DUL NAA1605-1665 Cat No NAA1605-1665	TITLE NON-TENSION ALUMINIUM ARMOUR RODS (NAA) FITTING COND. RANGE: Ø16.05Ø16.65 19/3.25 AAC/AAAC 19/0.128 AAC/AAAC 30/7/0.093 ASCR	DRAWN RN CHECKED MN DATE 30-04-2013 APPROVED AT	TE Connectivity 2/3 Corella Close Berkeley Vale NSW 2261 Australia				
DIST	—	I	NEW RELEASE	30-04-2013	RN	AT	MATERIAL DESC ALUMINIUM ALLOY			SIZE	PROJECTION	SCALE	DRAWING NO	SHEET	OF	REV	
POS	REV	REVISION RECORD			DATE	DWN	APVD	MATERIAL NO	MATL SPEC/STD/DRG NO	PROCESS SPEC HEAT TREAT/PLATING NO	A3	3RD ANGLE	NTS	NAA1605-1665-C	1	1	1