

REV. C
DCO 300855


TOLERANCES $\pm 0.10"$ - UNLESS
OTHERWISE SPECIFIED

COIL: @ 25°C	
RESISTANCE	80 OHMS $\pm 10\%$
NOMINAL VOLTAGE	12 VDC
MUST OPERATE	6.5 VDC MAX.
MUST RELEASE	3.3 VDC MAX., 1.2 VDC MIN.

ENVIRONMENT:	
VIBRATION	33 Hz TO 3000 Hz @ 30 g's
SHOCK	200 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES: OPERATE, RELEASE 10 MS MAX.
CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

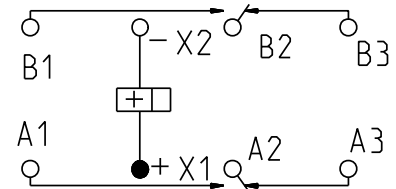

TERMINAL VIEW

CONTACT RATING: _____
10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE.
100,000 OPERATIONS

DR. B.D. 07MAR2008 | CK. J.M.B. 5/14/08



©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. _____ CATALOG ITEM _____
CUST. NO. _____ REV. _____

TE NUMBER
2-1617752-5

CII PART NUMBER
FCA-210-HX2