

REV. C
DCO 300853


TOLERANCES ±.010" - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C
 RESISTANCE _____ CURRENT: 30mA MAX.
 NOMINAL VOLTAGE 115 VAC - 50/400Hz
 MUST OPERATE 70.0 VAC MAX., 50/400Hz
 MUST RELEASE 25.0 VAC MAX., 8.0 VAC MIN., 50/400 Hz

ENVIRONMENT:
 VIBRATION 33 Hz TO 3000 Hz @ 30 g's
 SHOCK 200 g's 6 MS. DURATION
 TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE TIME 20 MS MAX.
 RELEASE TIME 50 MS MAX.
 CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

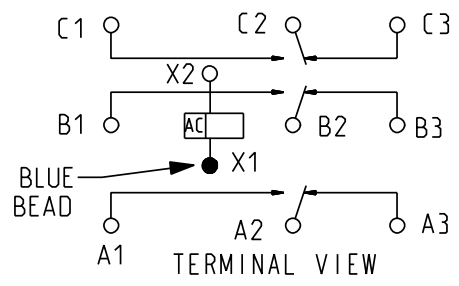

CONTACT RATING: 25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
 50,000 OPERATIONS

DR. B.D. 10APR2008 CK. J.M.B. 5/14/08

Tyco Electronics ©COPYRIGHT 2005
 TYCO ELECTRONICS CORPORATION
 ALL INTERNATIONAL RIGHTS RESERVED

CUST. _____ CATALOG _____
 CUST. NO. ---- REV. N/A

TE NUMBER 3-1617753-5

CII PART NUMBER FCA-325-AV9