


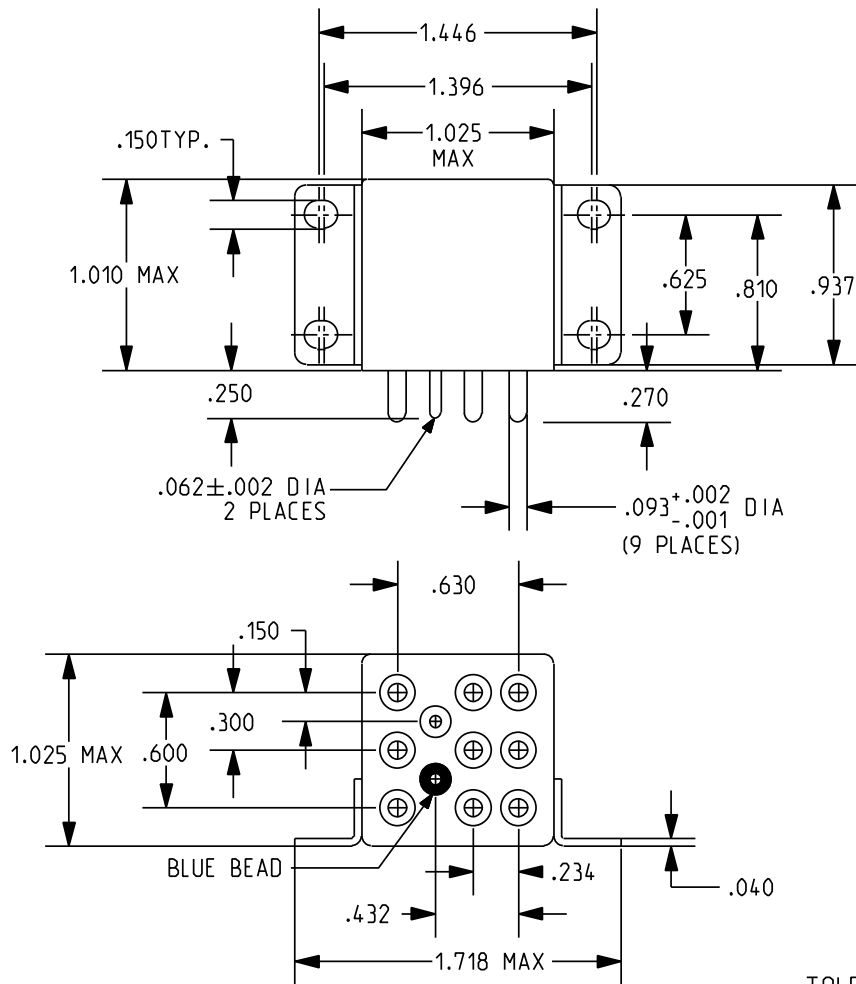

REV. C  
DCO 300853


TOLERANCES ±.010" - UNLESS  
OTHERWISE SPECIFIED

COIL: @ 25°C  
RESISTANCE 70 OHMS ±10%  
NOMINAL VOLTAGE 12 VDC  
MUST OPERATE 6.9 VDC MAX.  
MUST RELEASE 3.3 VDC MAX., 0.75 VDC MIN.

ENVIRONMENT:  
VIBRATION 33 Hz TO 3000 Hz @ 20 g's  
SHOCK 100 g's 6 MS. DURATION  
TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE, RELEASE 15 MS MAX.  
CONTACT BOUNCE 1 MS MAX.

## CUSTOMER DATA SHEET

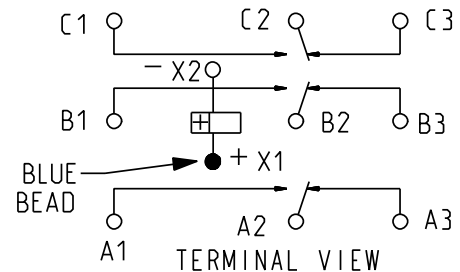

CONTACT RATING: 25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE  
50,000 OPERATIONS

DR. B.D. 10APR2008 CK. J.M.B. 5/14/08

**Tyco Electronics** ©COPYRIGHT 2005  
TYCO ELECTRONICS CORPORATION  
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG  
CUST. NO. REV. N/A  
TE NUMBER 4-1617753-3

CII PART NUMBER  
FCA-325-BX2