

REV. C  
DCO 301387


TOLERANCES  $\pm 0.010$ " - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C	
RESISTANCE	70 OHMS $\pm 10\%$
NOMINAL VOLTAGE	12 VDC
MUST OPERATE	6.5 VDC MAX.
COIL TRANSIENT SUPPRESSION: 42 VDC MAX.	
MUST RELEASE	3.3 VDC MAX., 0.75 VDC MIN.

ENVIRONMENT:	
VIBRATION	57 Hz TO 3000 Hz @ 20 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-70 °C TO +125 °C

NOTES:	OPERATE, RELEASE 15 MS MAX.
	CONTACT STABILIZATION 2.5 MS MAX.
	CONTACT BOUNCE 1 MS MAX.
	CONTACT BREAK BOUNCE 0.1 MS MAX.

### CUSTOMER DATA SHEET

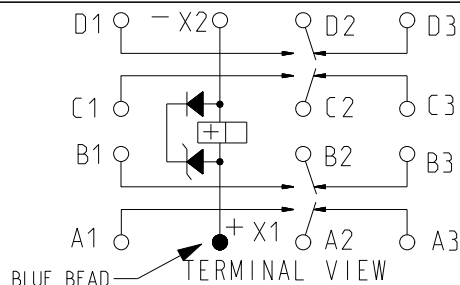

CONTACT RATING:	LOW LEVEL
10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE	
100,000 OPERATIONS	

DR. R.F. 21APR2011 CK. M.B. 26APR2011



CUST. QPL  
CUST. NO. M83536/16-016M REV. ----

TE NUMBER  
1-1617754-2

CII PART NUMBER  
FCA-410-1616M