
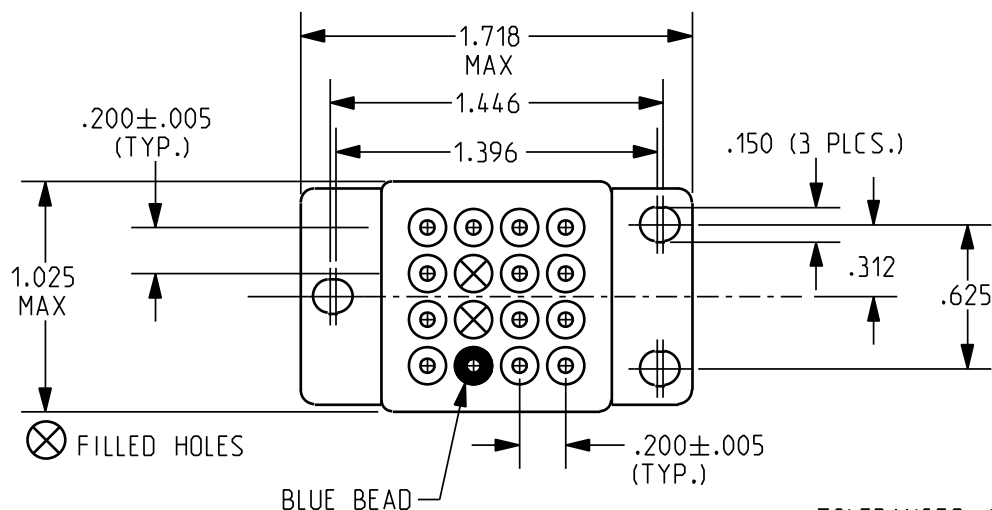


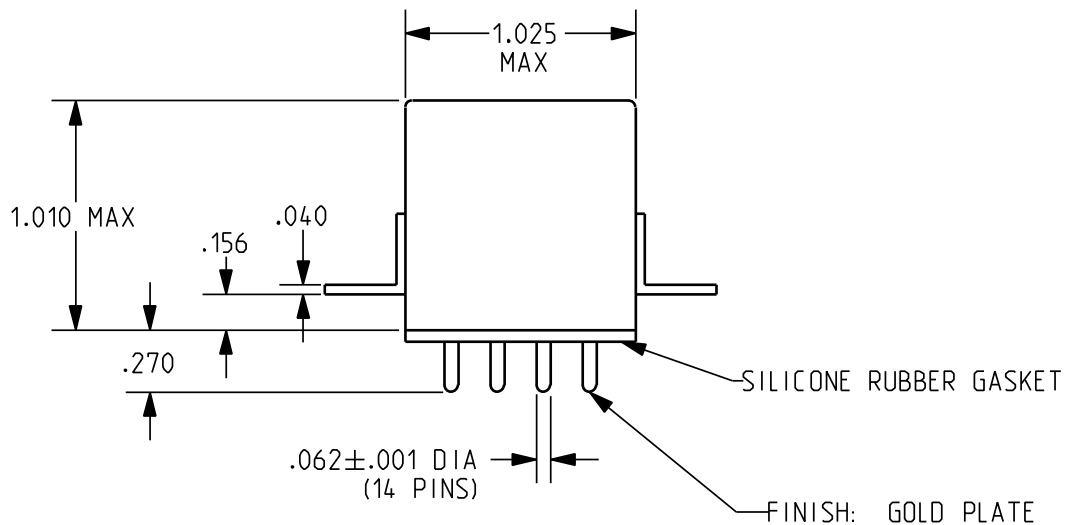

REV. B  
DCO 300859


TOLERANCES  $\pm .010"$  - UNLESS  
OTHERWISE SPECIFIED

COIL: @ 25°C  
RESISTANCE 290 OHMS  $\pm 10\%$   
NOMINAL VOLTAGE 28 VDC  
MUST OPERATE 13.5 VDC MAX.  
MUST RELEASE 5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:  
VIBRATION 10 Hz TO 3000 Hz @ 30 g's  
SHOCK 200 g's 6 MS. DURATION  
TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE, RELEASE 15 MS MAX.  
CONTACT BOUNCE 1 MS MAX.

## CUSTOMER DATA SHEET

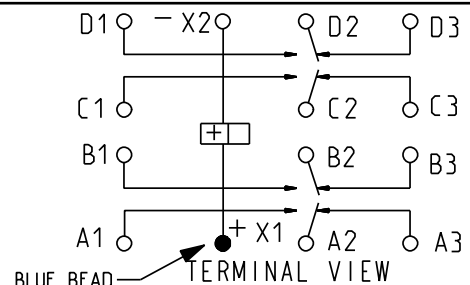

CONTACT RATING:  
10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE  
100,000 OPERATIONS

DR. B.D. 16MAY2008 CK. J.M.B. 5/19/08

**Tyco Electronics**

©COPYRIGHT 2005  
TYCO ELECTRONICS CORPORATION  
ALL INTERNATIONAL RIGHTS RESERVED

CUST. CATALOG ITEM  
CUST. NO. ---- REV. ----

TE NUMBER  
8-1617755-3

CII PART NUMBER  
FCA-410-AY3