

REV. B
DCO 300859



FILLED HOLES

.200 BLUE BEAD

TOLERANCES $\pm .010''$ - UNLESS OTHERWISE SPECIFIED

COIL: @ 25°C
 RESISTANCE _____ CURRENT: 40mA MAX.
 NOMINAL VOLTAGE _____ 115 VAC - 400 Hz
 MUST OPERATE _____ 70.0 VAC MAX., 400 Hz

 MUST RELEASE _____ 25.0 VAC MAX., 8.0 VAC MIN., 400 Hz


ENVIRONMENT:
 VIBRATION _____ 10 _____ Hz TO _____ 3000 _____ Hz @ _____ 30 _____ g's
 SHOCK _____ 200 _____ g's _____ 6 _____ MS. DURATION
 TEMPERATURE _____ -70 _____ °C TO _____ +125 _____ °C

NOTES: OPERATE TIME 20 MS MAX.

 RELEASE TIME 50 MS MAX.

 CONTACT BOUNCE 1 MS MAX.

CUSTOMER DATA SHEET

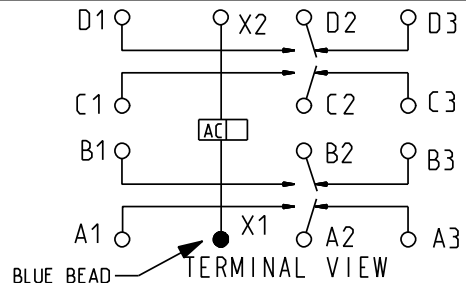

CONTACT RATING: _____
 10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
 100,000 OPERATIONS

DR. B.D. 16MAY2008 CK. J.M.B. 5/19/08

Tyco Electronics ©COPYRIGHT 2005
 TYCO ELECTRONICS CORPORATION
 ALL INTERNATIONAL RIGHTS RESERVED

CUST. _____ CATALOG ITEM _____
 CUST. NO. _____ REV. _____

TE NUMBER
1617756-6

CII PART NUMBER
FCA-410-CY8