

COIL: @ 25° C


RESISTANCE 160 OHMS ± 10%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 6.0 VDC
 MUST RELEASE .7 - 4.0 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS AT 30 g's
 SHOCK 100 g's 6 ± 1 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: _____

CUSTOMER DATA SHEET

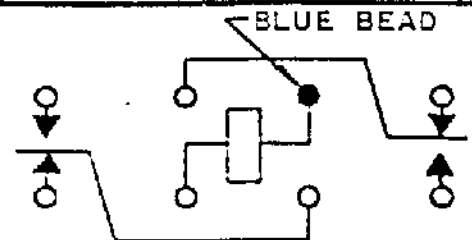

CONTACT RATING: LOW LEVEL TO
2 A @ 28 VDC 10000 OPERATIONS

DR. 8/18/86 JMB CK.



CUST. QPL
 CUST. NO. 39016/6-112L

TYPE HFW RELAY

HFW 1230G01