


REVISIONS

P	LTR	DESCRIPTION	DATE	DWN	APVD
	A	INITIAL	22DEC2017	YC	CW

ASSEMBLY STATE OF THE PRODUCT, FOR REFERENCE

产品装配状态，供参考

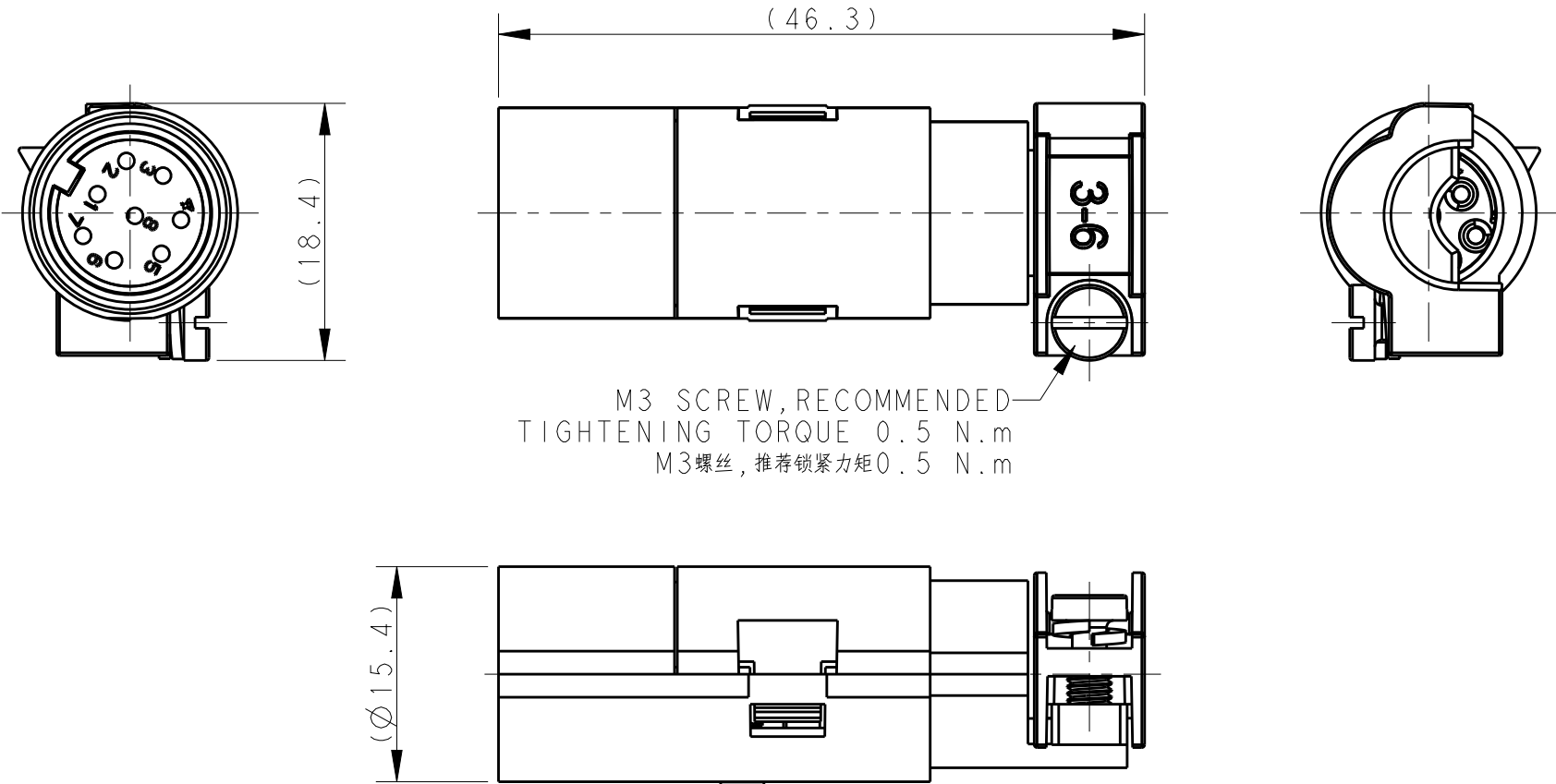


- NOTES:
- TECHNICAL CHARACTERISTICS:
INSULATION MATERIAL: PC
RATED VOLTAGE: 50V
RATED CURRENT: 5A
RATED IMPULSE VOLTAGE: 0.8KV
POLLUTION DEGREE: 3
FLAMMABILITY: UL94V-0
WIRE RANGE: 0.08-0.52 mm² (28-20 AWG)
CONTACT TYPE: CRIMP CONTACT
 - CONTACT NEED TO BE ORDERED SEPARATELY.
(ORDER No. REFER TO DRAWING:T20700X10XX000)

- 注释:
- 技术参数:
绝缘材料: PC
额定电压: 50V
额定电流: 5A
额定脉冲电压: 0.8KV
污染等级: 3
阻燃等级: UL94V-0
接线范围: 0.08-0.52 mm² (28-20 AWG)
接线类型: 冷压接
 - 端子需要单独订购.
(订货号参考图面: T20700X10XX000)

FOR Ø6-9.5mm CABLE
用于直径 Ø6-9.5mm 电缆线

FOR Ø3-6mm CABLE
用于直径 Ø3-6mm 电缆线

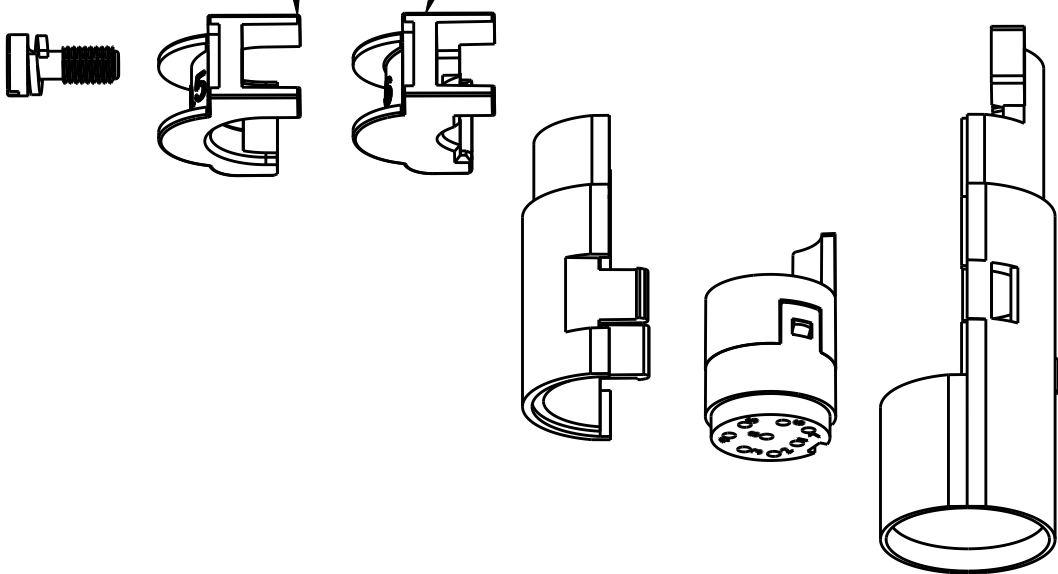

T2580081154-007	PIN-Q3-M	QUINTAX MALE CONTACT 8-POS QUINTAX 8-POS 公针
PART NUMBER 料号	PART DESCRIPTION 描述	

THIS DRAWING IS A CONTROLLED DOCUMENT.		DWN 22DEC2017 YORK CHEN			
		CHK 22DEC2017 GINO YAO			
		APVD 22DEC2017 CHRIS WANG	NAME QUINTAX CONTACT 8-POS PIN-Q3-M		
		PRODUCT SPEC 108-137067			
		APPLICATION SPEC 114-137067			
		WEIGHT -	SIZE A3	CAGE CODE 00779	DRAWING NO T2580081154007
		CUSTOMER DRAWING	SCALE 2:1	SHEET 1 OF 1	REV A

DIMENSIONS: mm		TOLERANCES UNLESS OTHERWISE SPECIFIED:	
		0 PLC	±-
		1 PLC	±-
		2 PLC	±-
		3 PLC	±-
		4 PLC	±-
		ANGLES	±-
MATERIAL -		FINISH -	