



TE Connectivity Products FIRST® Robotics Competition


TE Connectivity's products are a crucial part of an increasingly connected world. We can sense and connect data, power or signals moving through just about anything.

➔ Explore our catalogue of products on [TE.com](https://www.te.com)

Wire to Wire Connectors - Universal MATE-N-LOK




350767-1	03 POS UMNL CAP HSG V0	\$0.33
350778-1	02 POS UMNL CAP HSG	\$0.32
350780-1	04 POS UMNL CAP HSG	\$0.36
350866-1	01 POS UMNL CAP HSG	\$0.22

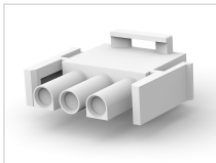

350766-1	03 POS UMNL PLUG HSG	\$0.27
350777-1	02 POS UMNL PLUG HSG	\$0.28
350779-1	04 POS UMNL PLUG HSG	\$0.28
350865-1	01 POS UMNL PLUG HSG	\$0.22



350551-2	UMNL SOK 20-14 AWG AUBR L/P	\$1.02
350689-2	UMNL SOK 24-18 AWG AUBR L/P	\$0.68
640310-6	UMNL SOK 12-10 AWG AU/PHBZ	\$1.39

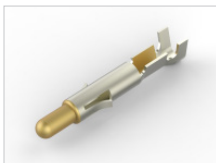


350552-2	UMNL PIN 20-14 AWG AUBR L/P	\$0.40
350690-2	UMNL PIN 24-18 AWG AUBR L/P	\$0.66
640309-6	UMNL PIN 12-10 AWG AU/PHBZ	\$1.37

Wire to Wire - ULTRA FAST



2-520184-2	250 ULTRA-FAST RCPT 22-18 TPBR	\$0.11
3-350820-2	250 ULTRA-FAST RCPT 16-14 TPBR	\$0.11
4-520448-2	250 ULTRA FAST REC 12-10TPBR	\$0.15

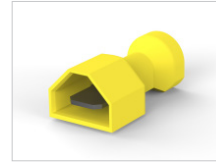

2-520103-2	250 ULTRA-FAST TAB 22-18 TPBR	\$0.19
3-520107-2	250 ULTRA-FAST TAB 16-14 TPBR	\$0.19
4-521098-2	250 ULTRA-FAST TAB 12-10 TPBR	\$0.24


Heat Shrink Tubing - VERSAFIT (shrink ratio 2-1)




1550634001	VERSAFIT-3/8-0-FSP black	\$0.20*
3584274005	VERSAFIT-3/16-4-SP yellow	\$0.17*
5058734012	VERSAFIT-3/16-9-SP white	\$0.16*
5058744001	VERSAFIT-1/4-0-SP black	\$0.20*
6479954003	VERSAFIT-3/16-2-SP red	\$0.17*
6519834003	VERSAFIT-1/4-4-SP yellow	\$0.22*
729987-000	VERSAFIT-3/8-6-FSP blue	\$0.23*

* Price for Heat Shrink Tubing per foot.


Wire to Wire/Panel Power Connectors

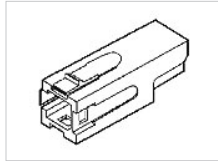

53884-1	HSG ASSY,PWR LK,SRS2,1 POS,BLU	\$2.25
53884-4	HSG ASSY,PWR LK,SRS2,1 POS,RED	\$2.63

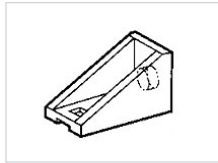

53886-1	PNL MT ADAPTER,FEMALE,POWER LK	\$2.85
53887-1	PNL MT ADAPTER,MALE,POWER LOCK	\$2.85

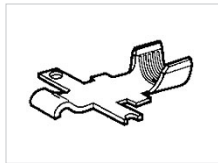

54330-1	CONTACT,PWR LK,SRS2,LS PC,SLDR, 6 awg max	\$1.14
53880-4	CONTACT,PWR LK,SRS2,LS PC,CRMP, 10-6 awg	\$0.89

Pushbutton Switch



1437568-7	MSPS103CO=MSPS-103C-BLK SPST	\$1.76
------------------	------------------------------	--------

Toggle Switches



1-1437558-0	MTA106D=(MSTA) SWITCH TOGGLE S, SPDT on-on	\$4.44
1-1437558-2	MTA106E=(MSTA) SWITCH TOGGLE S, SPDT on-off-on	\$6.82
2-1437558-0	MTA206N=(MSTA) SW TOG DPDT, DPDT on-on	\$6.52

Microswitch



1825043-3	UP01DTANLA04,MICROSWITCH,SNAP SPDT	\$0.47
------------------	---------------------------------------	--------

Ring, Spade and Splice Terminals



34067	PG BUTT SPLC 22-16COMM22-18MIL	\$0.17
34071	SPLICE,PG BUTT 16-14	\$0.12
34072	SPLICE,PG BUTT 12-10	\$0.22



34150	PG R 22-16 COMM 22-18 MIL 1/4	\$0.26
34162	TERMINAL,PG R 16-14 1/4	\$0.21
34855	TERMINAL,PG R 12-10 1/4	\$0.18
52041-1	TERMINAL,R PG 8 1/4	\$0.75
52042-3	TERMINAL,R PG 6 1/4	\$1.18



34156	PG SPD 22-16 COMM 22-18 MIL 10	\$0.29
34167	TERMINAL,PG SPD 16-14 10	\$0.14
34176	TERMINAL,PG SPD 12-10 10	\$0.39

Terminal Block



1-1546670-4	14P.437"" DR BARRIER,W/BND SCRW	\$4.73
1546670-2	2P .437"" DR BARRIER,W/BND SCRW	\$0.74
1546670-3	3P .437"" DR BARRIER,W/BND SCRW	\$1.04
1546670-4	4P .437"" DR BARRIER,W/BND SCRW	\$1.37
1546670-6	6P .437"" DR BARRIER,W/BND SCRW	\$2.03