



FRONT WHEEL LOADER


- CHARGING
- LOW-MEDIUM CURRENT - HIGH VOLTAGE ACCESSORIES
- HIGH CURRENT - POWER COMPONENTS

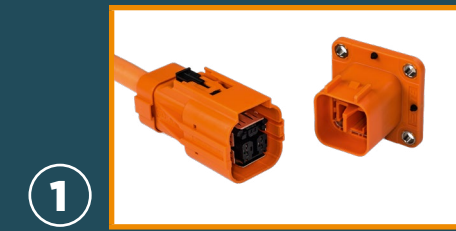


1 **AMP+ HVA 630**
 • 850V DC, 40A at +140°C

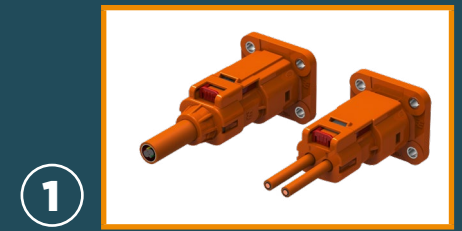


1 **AMP+ HVA 280**
 • High diversity (2P & 3P, multiple latching options, inline)
 • Up to 600V individually shielded wire and 850V multi-core wire
 • 40A at +85°C

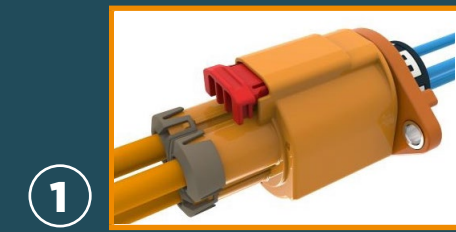

1 **HVA HD400**
 • Compact, rugged design offering transmission-level vibration performance (LV-S3)
 • 1000 VDC, 60 A (at 80°C), operating temperature of -40°C to +140°C

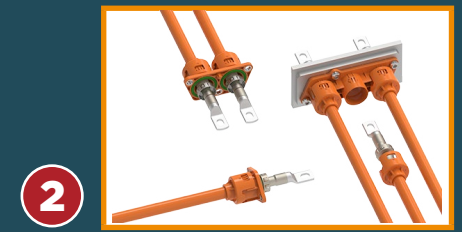

2 **IPT-HD**
 • Enhanced shielding design offering engine-level vibration performance
 • Operating temperature of -40°C to +125°C
 • Flexible assembly with single wiring harness

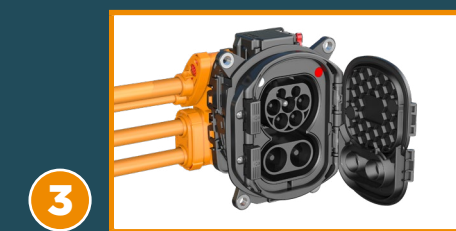

3 **Charging Inlet**
 • Available in kits and pigtails
 • IP67 rating, 250 VAC (at 32 A), and 1000 VDC (at 200 A)
 • Upgraded conductor sizes for fast charging - DC 70 mm² / PE 25 mm² / AC 6 mm²