



Connectors > Lighting Connectors > Street Lighting Controls > Street Lighting Accessories > Photo Control Cover



Lighting Product Type: **Cover**
Primary Product Color: **Natural**
Product Diameter: **81 mm [3.12 in]**
Lighting Connector Features Included: **Not Vented, Sleeve Compatible**

[All Photo Control Cover \(6\)](#)

Features

Product Type Features

Lighting Product Type	Cover
-----------------------	-------

Configuration Features

Lighting Connector Features Included	Not Vented, Sleeve Compatible
--------------------------------------	-------------------------------

Body Features

Primary Product Color	Natural
-----------------------	---------

Dimensions

Product Diameter	81 mm[3.12 in]
------------------	----------------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted



	Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2025 (250) SVHC > Threshold: UV-329 (.5% in 16981748073) Article Safe Usage Statements: Wash thoroughly after handling. Do not handle until all safety precautions have been read and understood. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1-2306130-2
COVER, LIGHT CONTROLLER, 81MM DIA., MED



TE Part # 2336396-2
ASSEMBLY, LIGHT CONTROLLER BASE, W/VENT



TE Part # 1-2213871-2
LIGHT CONTROLLER BASE ASSY, 81MM DIA,5POS



TE Part # 2213871-2
LIGHT CONTROLLER BASE ASSY, 81MM DIA,7POS



TE Part # 1-2336396-2
ASSEMBLY, LIGHT CONTROLLER BASE, W/VENT

Also in the Series | LUMAWISE Endurance N



Street Lighting Accessories(6)




Street Lighting Base Assemblies(18)



Street Lighting Open & Shorting Caps (1)




Street Lighting Power Management(6)

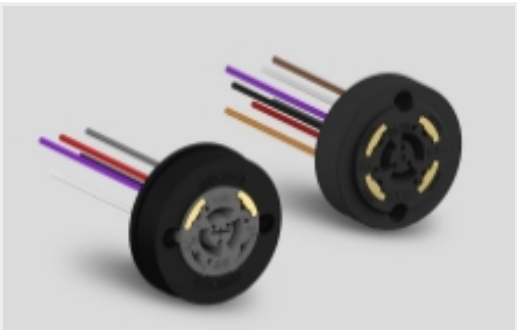


Street Lighting Receptacles(24)

Customers Also Bought

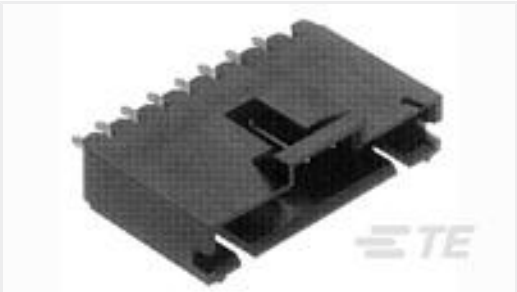

TE Part #5-103908-5
06 MTE HDR SRST LATCH W/HLDWN

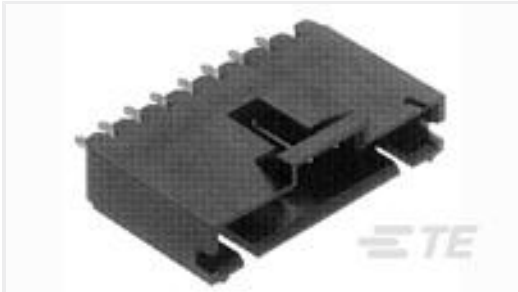


TE Part #6-103908-3
14 MTE HDR SRST LATCH W/HLDWN



TE Part #292304-1
STD USB TYPE B, R/A, T/H



TE Part #644752-6
06P MTA156 HDR ASSY SQ STR F/L

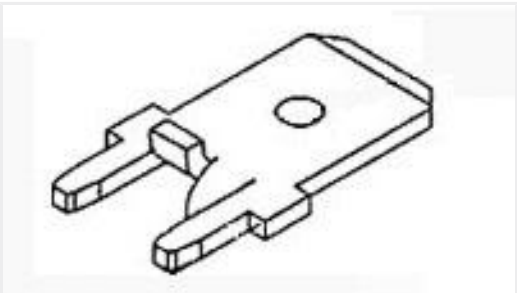

TE Part #1217861-1
250 FASTON,PCB TAB,TCBR



TE Part #1415898
RTS3T012



TE Part #1473005-1
SEMI HARD TRAY DDR SOCKET 200P



TE Part #1-6609115-1
3EGG1-1 SHORT VERS=F7381D



TE Part #2466136-4
LUMAWISE Endurance N+ 81mm, 7P, w/o vent



TE Part #2213871-2
LIGHT CONTROLLER BASE ASSY, 81MM DIA,7POS

Documents



Product Drawings

COVER, LIGHT CONTROLLER, 81MM DIA., MED

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1-2306130-1_D.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1-2306130-1_D.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1-2306130-1_D.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

LUMAWISE STREET LIGHT DIMMING AND CONTROL QUICK REFERENCE GUIDE

English

LUMAWISE ENDURANCE N CONTROL BASE, SLEEVE AND COVER

English

Product Specifications

Application Specification

English

Agency Approvals

UL_CERT_CB_US_37285_C1

English