


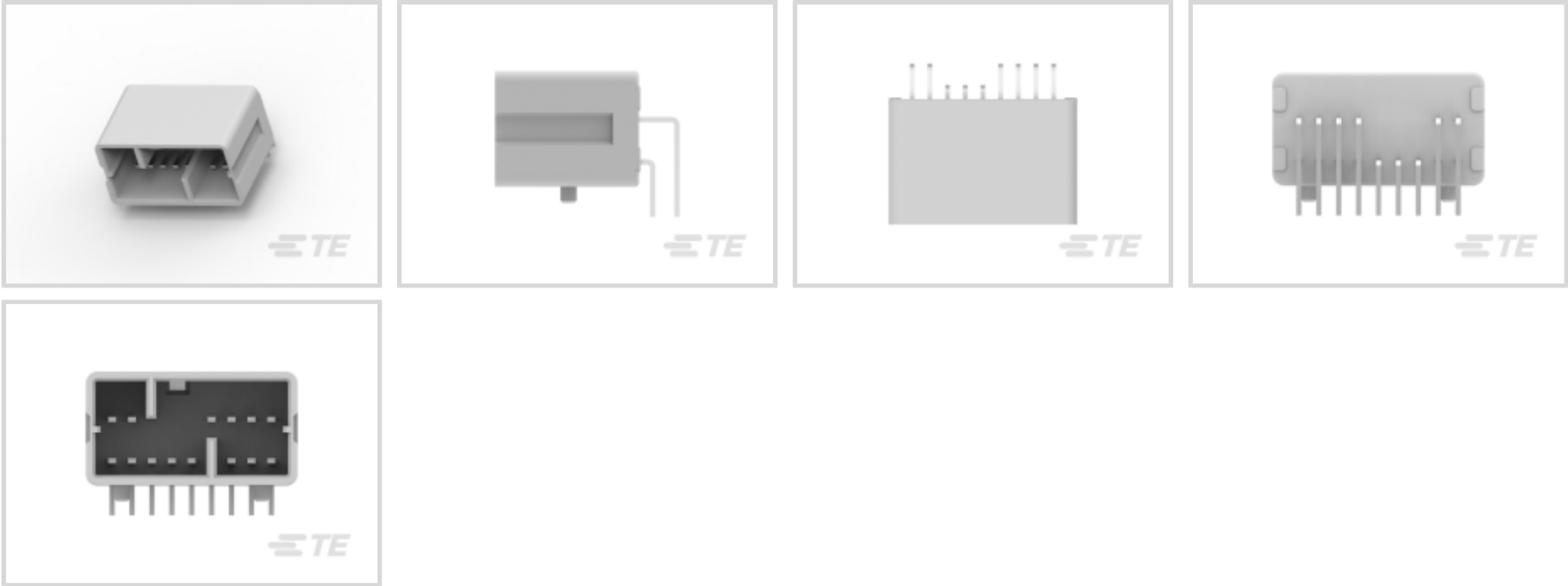

Product Compliance

For compliance documentation, visit the product page on TE.com>


EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2025 (250) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Wave solder capable to 240°C

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



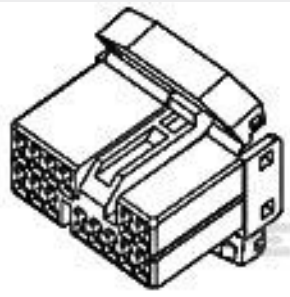


TE Part # 1746847-1
040 MLC 14POS PLUG HSG

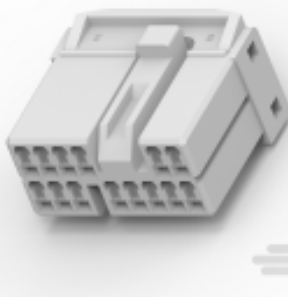

TE Part # 917531-1
040 MLC T.F. PLUG HSG 14P NATU

Customers Also Bought

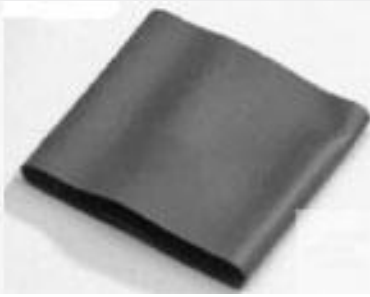

TE Part #663099J001
V2-22.0-0-FSP-SM




TE Part #440054-9
2.0MM,HDR,9POS,VERTICAL




TE Part #CAT-HPCH5372
High Pin Count Header



TE Part #CAT-SIGH262
Signal Header

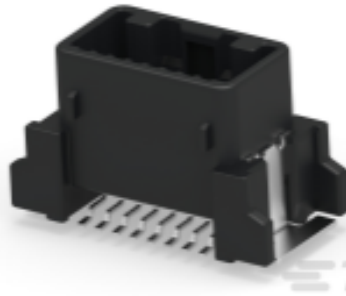


TE Part #1717396-3
0.64 SMD 16P CAP ASSEMBLY V-TYPE Tray

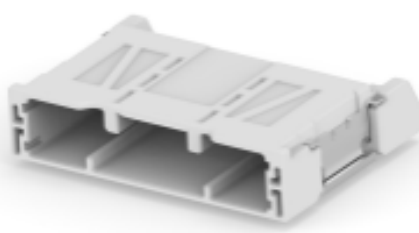

TE Part #1939082-9
0.5/1.5 HYBRID 16POS SMT CAP ASSY



TE Part #5-2203452-1
MALE ASM, 1 POS, VERT, PCB, KEY A

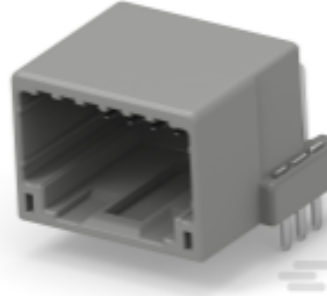

TE Part #2297730-1
0.64 12POS CAP ASSY SMT REVERSE LOCK

Documents

Product Drawings

040 MLC CAP ASSY 14P H LOW PRO

Japanese

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_917604-1_C.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_917604-1_C.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_917604-1_C.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.



Datasheets & Catalog Pages
MULTILOCK Connector System

English

Product Specifications
Product Specification

English

.040 Series Multi-Lock I/O Connector (.040 ML I/O)

English

Instruction Sheets
Instruction Sheet (non U.S.)

English

040 SERIES MULTI-LOCK CONNECTOR

English